


PRODUCT DATA SHEET

FR6 LITHIUM ULTIMATE



Ref.no. LI-UL-LR6-V23-09

Date of issue: 1 October, 2023

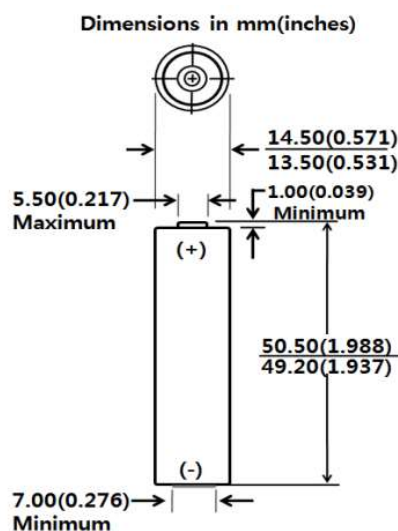

Type Designation	IEC: LR6 / AA	
Made in	China	
Chemical System	Lithium and Iron Disulfide battery	
Dimensions	Diameter: 13.5 – 14.5 mm	Height: 49.2 – 50.50 mm
Nominal Voltage	1.5 V	
Average Weight	15 g	
Compliant to	IEC 60086-1, IEC 60086-4, EU directive 2006/66/EC	
Storage Temp. Range	+10°C (50°F)- +25°C (77°F)	
Operating temp Range	-30°C (-22°F)- +60°C (140°F)	
Lithium Content	<1	
Rated Capacity	2200 mAh	


Appearance and terminal

Battery shall be clean and have no dirt, no leakage, and no deformation which may affect their performance and actual use and shall have clearly visible markings.




FR6 LITHIUM ULTIMATE

Discharge curve

Temperature Effects on Capacity / Constant current discharge

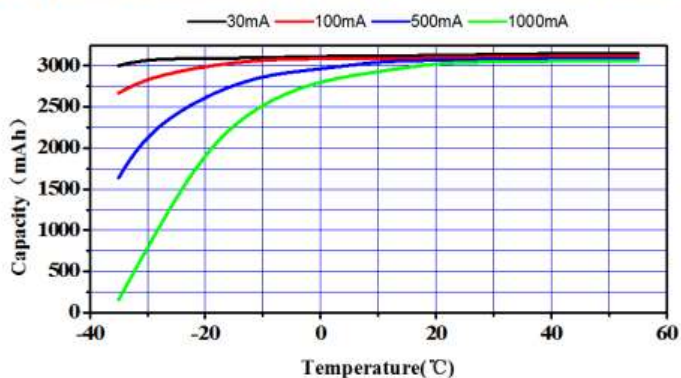


Discharge curve / Constant current discharge

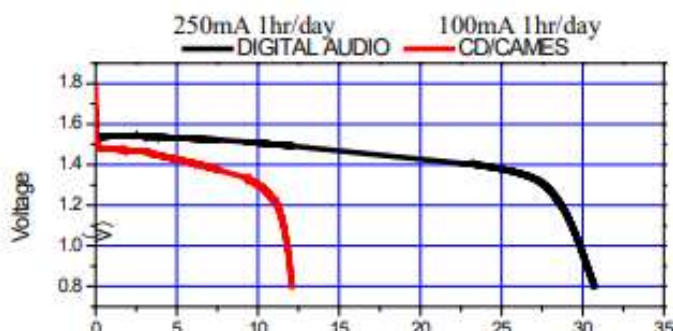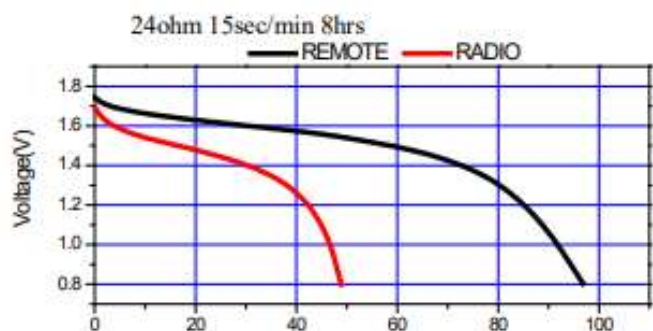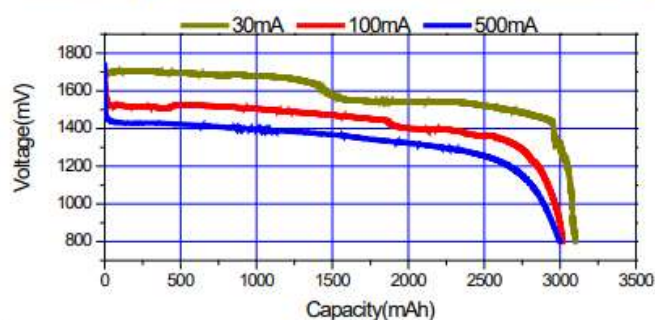

PORTABLE LIGHTING TOY

500mA 2min/13min 3.3ohm constant 3.9ohm 1hr/day

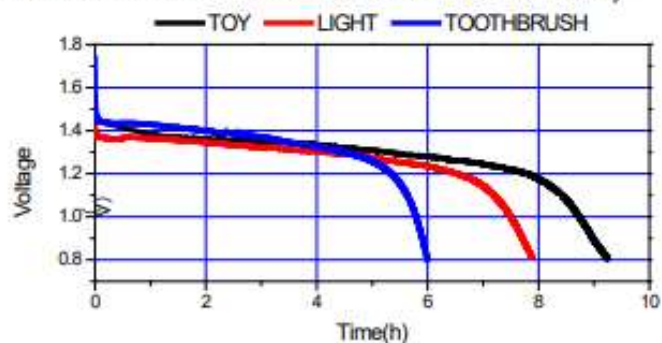

DIGITAL CAMERA PHOTOFL

1.5W/0.65W/2S/28S 1KmA 10S/min 1hr/Da

