



KURZANLEITUNG


Artikel-Nr.: 843340 / DALI/PUSH, 230V Triac-Dimmer, max. 400W

Sehr geehrter Kunde,

vielen Dank das Sie sich für den Kauf unseres Produktes entschieden haben. Es erfüllt die geltenden Anforderungen der europäischen und nationalen Richtlinien. Technische Daten können ohne Vorankündigung geändert werden. Irrtümer vorbehalten. Die Installation darf ausschließlich von einer qualifizierten Elektrofachkraft ausgeführt werden. Bei Sach- und Personenschäden durch Nichtbeachten der Produkt-Hinweise und Montageanleitung, durch unsachgemäße Handhabung der vorgenommene Änderungen übernehmen wir keine Haftung.

Bitte beachten Sie auch die vollständige Bedienungsanleitung unter dem oben abgedruckten QR-Code/Link.

Technische Beschreibung:

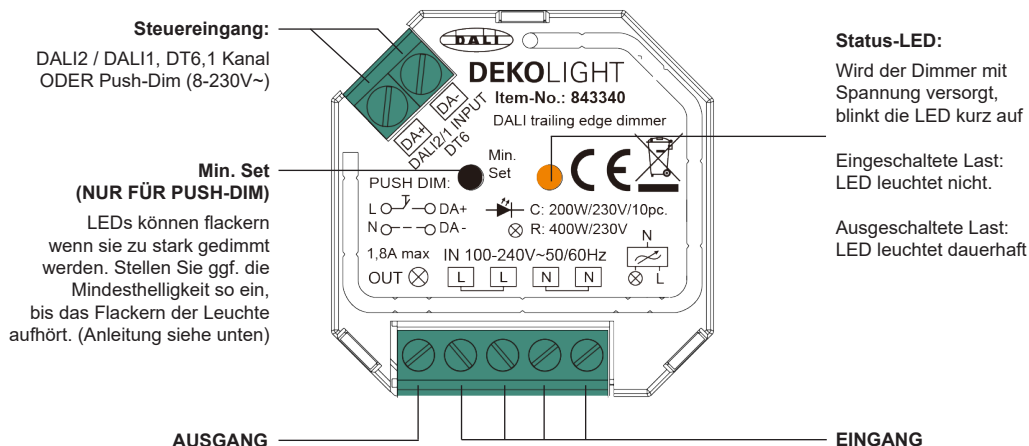

Technische Daten:

Ein/Ausgangsspannung	Ausgangsstrom	Dimmertyp	Schutzklasse	IP Schutzklasse	DALI2 / DALI1	Maße (LxBxH)
100-240 V AC 50/60Hz	max. 1.8 A	Phasenabschnitt	II	IP20	DT6, max.2mA	45,5x45x20,3mm

In Übereinstimmung mit IEC 62386-101:2014, IEC 62386-102:2014, IEC 62386-207 Ed2.

Lastarten und Leistung:

Symbol Lastart	Zeichen	Beschreibung Lastart	Maximale Leistung	Hinweise / Einschränkungen
	C	Dimmbare LED-Leuchtmittel und dimmbare Netzgeräte	200W / 230V 100W / 120V	Maximal 10 Vorschaltgeräte oder LED-Leuchtmittel je Dali-Triac-Dimmer!
	R	Glühlampen und HV-Halogenlampen	400W / 230V 200W / 120V	Keine Einschränkung bzgl. maximaler Menge zu betreibender Leuchtmittel.

Mindesthelligkeit speichern (FUNKTION NUR BEI PUSH-DIM):

Stellen Sie die gewünschte Helligkeit mit dem Push-Taster ein. Zum speichern, drücken Sie die Taste „Min. Set“ am Dimmer solange, bis das Licht blinkt. Danach kann nur noch zwischen der gespeicherten Mindesthelligkeit und der maximalen Helligkeit gedimmt werden.


Mindesthelligkeit löschen (FUNKTION NUR BEI PUSH-DIM):

Stellen Sie die maximale Helligkeit mit dem Taster ein und drücken Sie dann die Taste „Min. Set“ am Dimmer solange, bis das Licht blinkt.

Elektrischer Anschluss:

Schalten Sie die Stromversorgung vor der Installation aus und sichern Sie diese gegen wieder einschalten. Bevor Sie nach erfolgter Montage wieder einschalten, überprüfen Sie die Verkabelung und stellen Sie sicher, dass alle Kabel richtig angeschlossen sind, da der Dimmer ansonsten beschädigt werden kann. Beachten Sie zwingend die Installationsvorschriften in Ihrem Land.

Steuerung mit DALI:

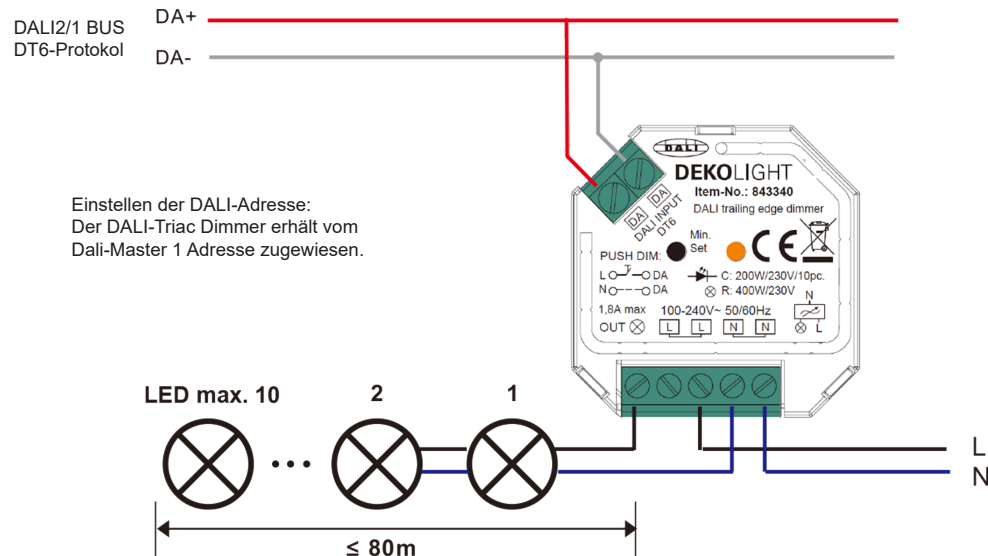


Schalten/Dimmen mit PUSH-Taster:

Funktionsweise:

- Push-Taster KURZ drücken: EIN-/AUSSCHALTEN
- Push-Taster LANG drücken: HELLGKEIT STUFENLOS DIMMEN (hell-dunkel-hell).

Halten Sie den Taster bis zur gewünschten Helligkeit gedrückt. Wiederholen Sie ggf. den Vorgang erneut um die Helligkeit zu erhöhen oder zu verringern.

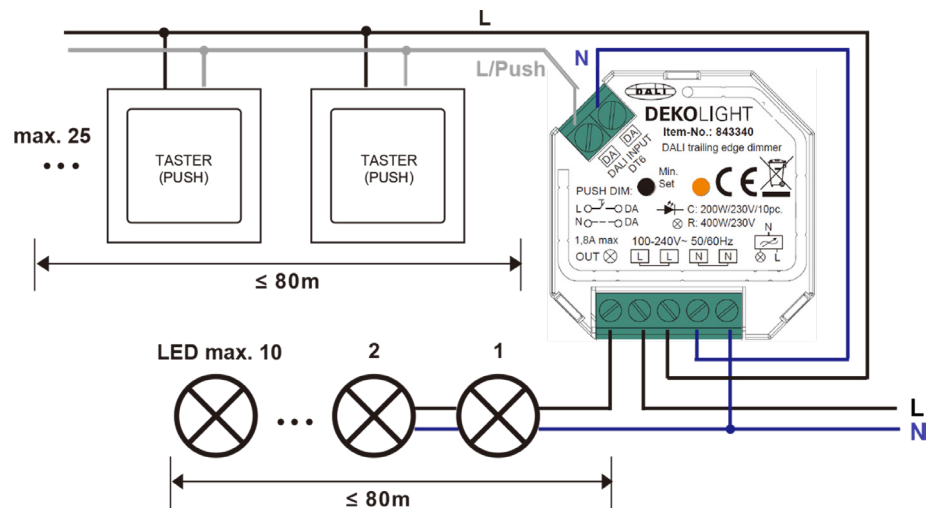



QUICK START GUIDE


Article-No.: 843340 / DALI/PUSH, 230V Triac-Dimmer, max. 400W

Dear Customer,

Thank you for choosing to purchase our product. It meets the applicable requirements of European and national directives. Technical data are subject to change without notice. Errors excepted. The installation may only be carried out by a qualified electrician. We assume no liability for property damage or personal injury caused by failure to follow the product instructions and assembly instructions or by improper handling of the changes made.

Please also note the complete operating instructions under the QR code/link printed above.

Technical Description:

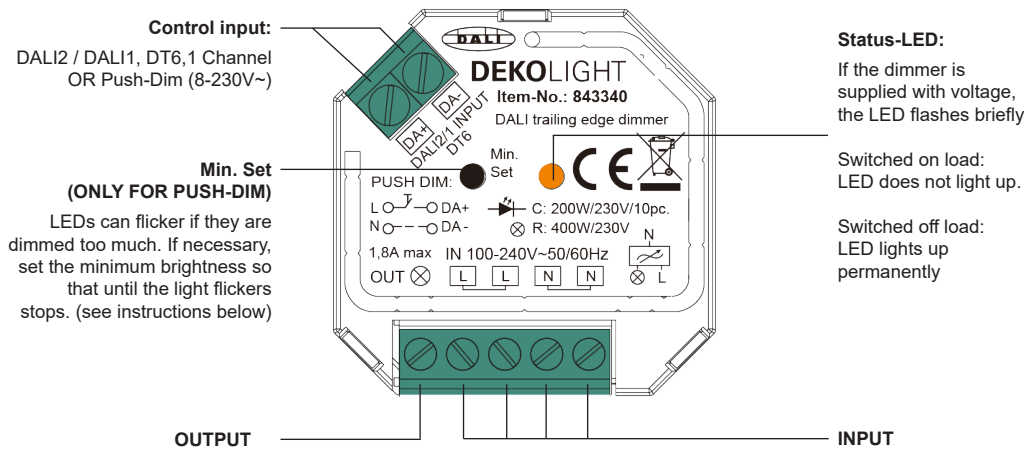

Technical Data:

Input/output voltage	Output current	Dimmer type	Protection class	IP protection	DALI2 / DALI1	Dimensions
100-240 V AC 50/60Hz	max. 1.8 A	trailing edge	II	IP20	DT6, max.2mA	45,5x45x20,3mm

In accordance with IEC 62386-101:2014, IEC 62386-102:2014, IEC 62386-207 Ed2.

Load types and performance:

Symbol Load type	Symbol	Description of load type	Maximum Performance	Notes/Limitations
	C	Dimmable LED bulbs and dimmable power supplies	200W / 230V 100W / 120V	<u>Maximum</u> of 10 ballasts or LED bulbs each Dali Triac dimmer!
	R	light bulbs and HV halogen lamps	400W / 230V 200W / 120V	No restrictions regarding maximum amount operating light source.

Save minimum brightness (FUNCTION ONLY FOR PUSH-DIM):

Set the desired brightness using the push button. To save, press the "Min" button. Set" on the dimmer until the light flashes. After that, you can only dim between the saved minimum brightness and the maximum brightness.


Delete minimum brightness (FUNCTION ONLY FOR PUSH-DIM):

Set the maximum brightness using the button and then press the "Min" button. Set" on the dimmer until the light flashes.

Electrical connection:

Before installation, switch off the power supply and secure it against being switched on again. Before you switch on again after installation, check the wiring and make sure that all cables are connected correctly, otherwise the dimmer can be damaged. It is imperative that you follow the installation regulations in your country.

Control with DALI:

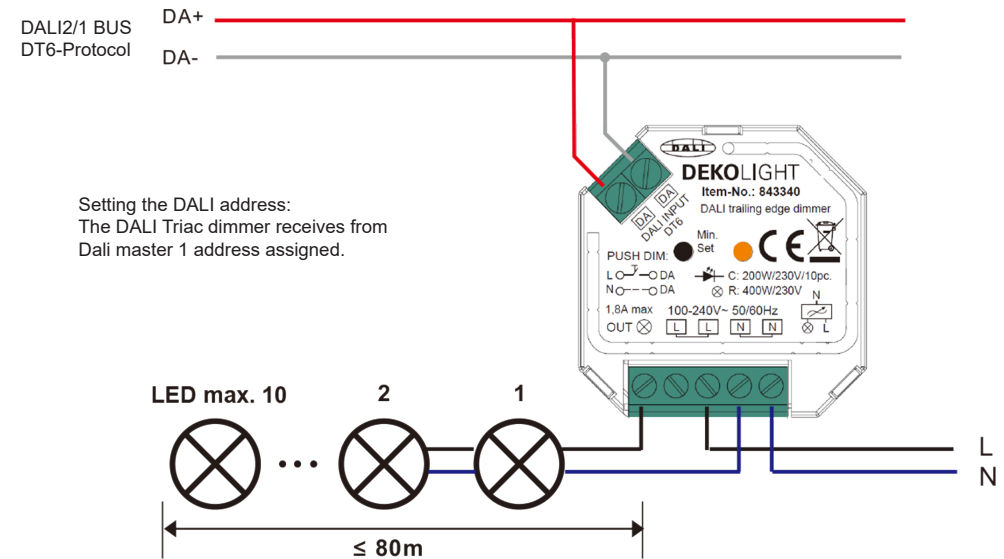

Switching/dimming with PUSH button:

Functionality:

- SHORTLY press the push button: SWITCH ON/OFF
- LONG press the push button: CONTINUOUSLY DIMMING BRIGHTNESS (light-dark-light).

Press and hold the button until the desired brightness is reached. If necessary, repeat the process again to increase or decrease the brightness.

