




Doorbell 2S Kit

2K Wire-Free Video Doorbell



With 3MP/2K live monitoring, ultra wide-view lens with 30° pan features, Doorbell 2S ensures every corner in front of door completely covered. With 5000mAh rechargeable battery, Doorbell 2S is 100% wire-free, waterproof and easy to install. PIR, AI human detection and loitering detection quickly find targets and immediately sends a notification to you. Doorbell 2S supports to talk with variable voice and customizable quick voice reply to protect your privacy. Indoor Chime DS2S works as a Wi-Fi extender and a local storage, providing stable network for the doorbell and upgraded protection for the recorded footage.

-
- | | | |
|---|---|--|
|  3MP 2K Video
See more details than 1080P |  100% Wire-Free
Chime works as Wi-Fi extender. Free of network cabling and power wiring hassles. |  Rechargeable Battery
5000mAh Rechargeable Battery
DC 5V Power Supply (Type-C Port) |
|  30° Pan Lens and Smart Tracking
Reduce blind area in front of door.
Track moving targets in time. |  PIR + Human Detection
Discerns people and motion detection.
More accurate alerts. |  Auto Power Saving Mode
Keep the doorbell working in low battery condition. |
|  Two-way Talk with Variable Voice
Protect your privacy, especially for children and solitary people |  Loitering Detection
Detect people loitering in door area.
Reduce the frequency of notifications. |  Optional Hardwired Power Supply
Upgrades your traditional doorbells.
Power Supply with 8~24VAC, ≥5VA. |
|  Waterproof
Weatherproof for outdoor conditions |  Flexible and Secure Storage
Both cloud and Micro SD Card Local Storage (up to 512GB) on Chime. |  Multiple Ringtones Available
Different chime ringtones are available
Snooze schedules and volume can be set |
-

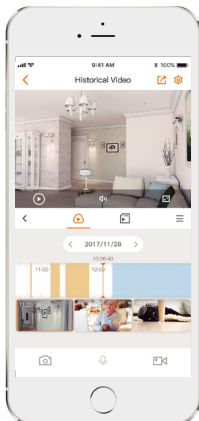

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

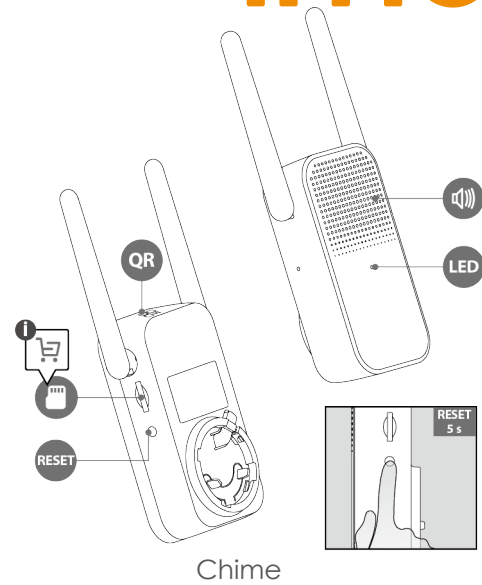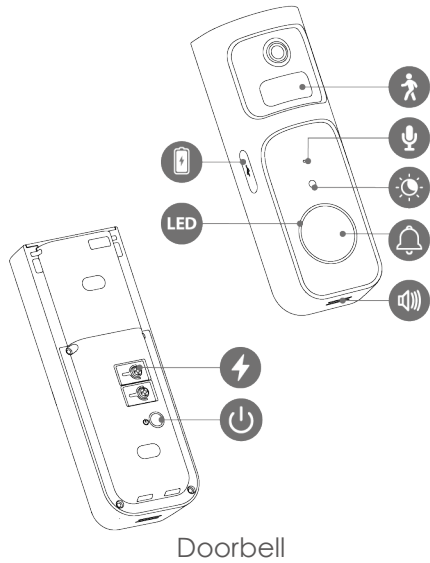

Specifications

Video Doorbell

1/2.8" Progressive CMOS
3MP (2048 x 1536)
Night Vision: 5m(16.5ft) Distance
2.3 mm Fixed Lens, 30° Pan
Field of View : 125° (H), 98° (D), 166° (D)
5000mAh Rechargeable Battery

Video & Audio

Video Compression : H.265
Up to 15fps Frame Rate
Two-way Talk
8x Digital Zoom

Notice Management

Doorbell Call Notification
PIR Motion Detection
Loitering Detection
Auto Power Saving Mode

Network

Wi-Fi:IEEE802.11b/g/n, 2.4GHz
Chime works as the Wi-Fi extender for the Doorbell
imou App: iOS, Android

Auxiliary Interface

Video Doorbell:
Built-in Mic & Speaker
Power On / Off Button

Chime:
Micro SD Card Slot (up to 512GB)
Built-in Speaker
Reset Button

General

Video Doorbell:
Charging Power: DC 5V 1A, Type-C Port
Optional Hardwired Power Supply (8~24VAC, ≥5VA)
Power Consumption: up to 2.27W
Working Environment:-20° C~+50° C, Less Than 95%RH
Charging Temperature:0° C~+45° C
Dimensions: 150 × 55 × 50.3 mm (5.9 × 2.2 × 2.0 inch)
Weight: 237.5g (0.5 lb)
CE, Weatherproof

Chime:
AC Power Supply: 100~240 VAC
Power Consumption: up to 3W
Working Environment:-10° C~+45° C, Less Than 95%RH
Dimensions: 95.5 × 65.1 × 30.2mm (3.8 × 2.6 × 1.2 inch)
Weight: 79g (0.2 lb)
CE

What's in the box

- 1x Doorbell
- 1x Quick Start Guide
- 1x Surface Mounting Bracket
- 1x USB Charging Cable
- 3x Wire Nuts
- 2x 3M Glue
- 1x Chime Plug
- 1x Screw Package
- 1x Pin
- 1x Installation Position Map
- 2x Extension Wire
- 1x Jumper Wire
- 1x Chime

