



Cell PT With Solar Panel

For Continuous Charging



3MP H.265 Wi-Fi Battery Camera


The Cell PT set up with 2.4GHz Wi-Fi is a 100% wire-free rechargeable camera that delivers well-rounded home protection for up to almost 365 days on one single charge. With 2K, IP66 Weatherproof, the Cell PT outdoor provides a huge field of view so you can see every corner of your home. Equipped with a built-in microphone and speaker, the outdoor camera allows you to listen and talk to anyone. Easy wireless installation—no need to connect your security camera to electrical wiring. Compatible with Amazon Alexa. 3W Solar Panel uses power from the sun to continuously charge Cell PT providing non-stop peace of mind.

- 3MP QHD Video**
See more details than 2K
- 100% Wire-Free**
Supports 2.4 GHz Wi-Fi, Free of network cabling and power wiring hassles
- 15000mAh Rechargeable Battery**
DC 5V Power Supply Rechargeable Battery Power
- Siren & Spotlight**
Once an intruder is detected, the camera's spotlights and siren will be triggered or manually activated to warn off the would-be criminal.
- PIR+Human Detection**
Discerns people and motion detection. More accurate alerts.
- Low-Battery Notifications**
Informs you when battery level goes down to 20%, 10%, so you can charge it in time.
- Two-way Talk**
Using variable sound when taking real-time talk with people in front of the camera
- Auto Tracking**
Track moving targets in time.
- Type-C**
Type-C interface with better adaptability.
- IP66**
Weatherproof for outdoor conditions
- Flexible and Secure Storage**
insert a micro SD card for local storage (up to 256GB).
- Works with Solar Panel**
Works with Imou Solar Panel for battery charging



Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and playback anytime anywhere.

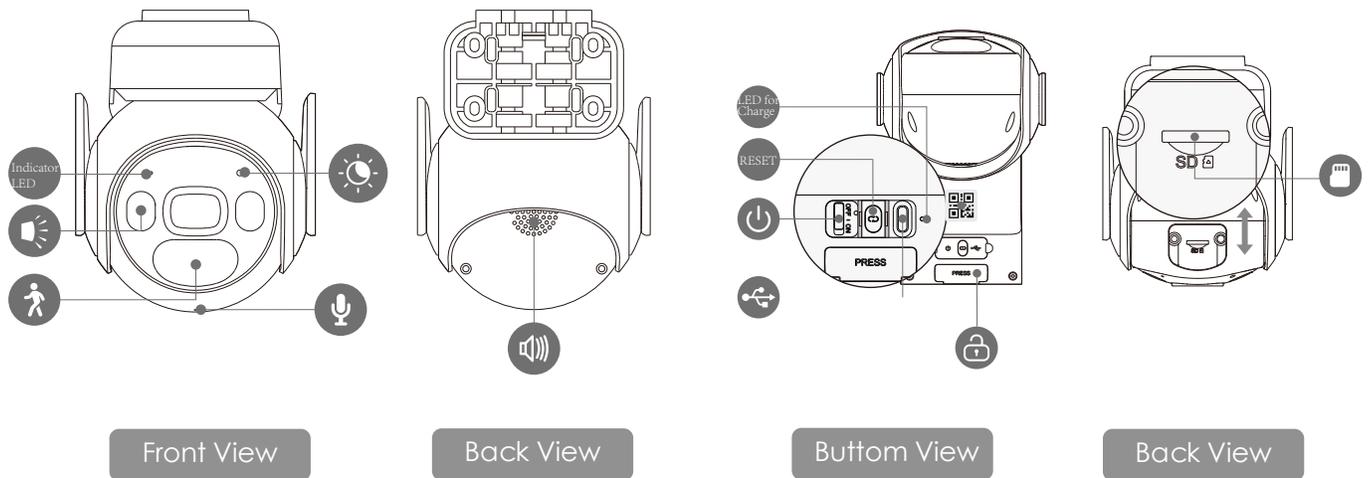

Specifications

Camera

1/2.8" Progressive CMOS
 3MP(2304*1296)
 Night Vision: 20m(65ft) Distance
 3.6mm Fixed Lens
 Field of View: 3.6mm: 88° (H), 45° (V), 107° (D)
 (330° Pan, 90° Tilt)
 15000mAh Rechargeable Battery

Video & Audio

Video Compression : H.265/H.264
 Up to 15fps Frame Rate
 8x Digital Zoom
 Two-way Audio

Notice Management

Motion Detection
 Human Detection
 Configurable Region
 Performance mode

Storage

Local Storage: SD Card (Up to 256GB)
 Cloud Storage: Imou Subscription Plan
 Record, view, and save events in your Imou app with a 31 day trial of the Imou Subscription Plan.

Network

Wi-Fi: IEEE802.11b/g/n, 50m Open Field
 Imou App: iOS, Android

Auxiliary Interface

Built-in Mic & Speaker
 Power on / off Button
 Reset Button
 Micro SD Card Slot (up to 256GB)

General

Material: Plastic
 DC 5V 2A Power / Imou Solar Panel Supply
 Power Consumption: < 3.5W
 Operating Temperature: -20°C ~ +50°C, Less Than 95%RH (-4°F ~ 122°F)
 Charging Temperature: -0°C ~ +45°C (32°F ~ 112°F)
 Camera Dimensions: 177*110*142 mm (6.97*4.33*5.59 inch)
 Camera Weight: 718g (1.58 lb)
 CE, UKCA, WWA

What's in the box

- 1x Camera
- 1x Power Cable(1m)
- 1x Mounting Template
- 4x Screws
- 1x Quick Start Guide
- 1x Mounting Bracket
- 4x Expansion Screw

