

imou



Cell 3C All in One With Solar Panel

3MP H.265 Wi-Fi Battery Camera


The Cell 3C All in One is a 100% wire-free rechargeable camera integrated 2.2W solar panel so that it can deliver well-rounded home protection for almost 365. With a posture like that of a guardian, this feature-packed solar camera fits just about anywhere. 2K, IP66 Weatherproof, Smart Full-Color Night Vision, Compatible with Amazon Alexa. 2 hours of daily direct sunlight extends battery life to near-infinite power.

- | | | |
|---|--|---|
|  3MP QHD Video
See more details than 1080P |  100% Wire-Free
Supports 2.4 GHz Wi-Fi, Free of network cabling and power wiring hassles |  Rechargeable Battery
DC 5V Power Supply Rechargeable Battery Power |
|  Siren & Spotlight
Once an intruder is detected, the camera's spotlights and siren will be triggered or manually activated to warn off the would-be criminal. |  PIR+Human Detection
Discerns people and motion detection. More accurate alerts. |  Low-Battery Notifications
Informs you when battery level goes down to 20%, 10%, so you can charge it in time. |
|  Two-way Talk
Using variable sound when taking real-time talk with people in front of the camera |  Privacy Mode
Device goes to sleep to protect your personal privacy |  Type-C
Type-C interface with better adaptability. |
|  IP66
Weatherproof for outdoor conditions |  Flexible and Secure Storage
insert a micro SD card for local storage (up to 256GB). |  Works with Solar Panel
Works with Imou Solar Panel for battery charging |




Stay close with what you care


With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

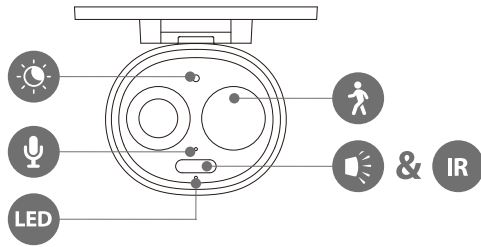

Front View

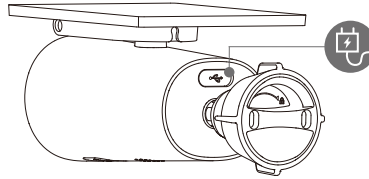

Back View

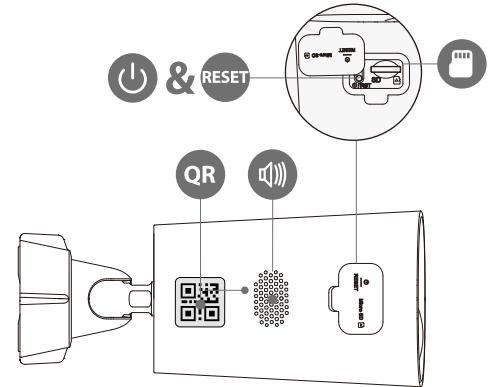

Bottom View

Specifications

Camera

1/2.8" Progressive CMOS
3MP(2304*1296)
Night Vision: 15m(49ft) Distance
2.8mm Fixed Lens, Max. Aperture F2.0
Field of View : 98° (H), 54° (V), 121° (D)
5000mAh Rechargeable Battery

Video & Audio

Video Compression : H.265
Up to 15fps Frame Rate
8x Digital Zoom
Two-way Audio

Notice Management

Motion Detection
Human Detection
Configurable Region
Work mode

Storage

Local Storage: SD Card Slot (Support SD Card up to 256GB)
Cloud Storage: Imou Subscription Plan
Record, view, and save events in your Imou app with a 31 day free-trial of the Imou Subscription Plan

Network

Wi-Fi:IEEE802.11b/g/n,50m Open Field
Imou App: iOS, Android

Auxiliary Interface

Built-in Mic & Speaker
Power on / off Button
Reset Button
SD Card Slot

General

DC 5V 2A Power / Imou Solar Panel Supply
Power Consumption:<3.5W
Operating Temperature:-20℃~+50℃ (-4°F~122°F)
Charging Temperature:-0℃~+45℃ (32°F~112°F)
Camera Dimensions: 168.1 × 96.8 × 69.5mm (6.61 × 3.81 × 2.74inch)
Camera Weight: 360g (0.79lb)
MSDS、CE、Alexa

What's in the box

- 1x Camera with Solar panel
- 1x Power Cable
- 1x Quick Start Guide
- 1x Install stickers
- 1x Power extension cord
- 1x Screw and Wall Anchor pack

