



Einsatzbereich: 723 htec
740 htec

Best.-Nr.: 60.278.11

Elektrische Werte

Übertragungsrate 100Mbit (cat5)
Durchgangswiderstand < 15 mOhm

Werkstoff

Kontakt Messing, vergoldet

Anschluss


Anschlussart crimp
Anschlussbereich 0,03 - 0,34 mm²
Abisolierlänge 4 mm
Litzendurchmesser max. Ø1,6 mm

Mechanische Werte

Steckzyklen 500

Werkzeuge (nicht im Lieferumfang enthalten)

digitale Crimpzange für Best.-Nr.: C0.235.00
0,6mm Kontakte (für 0,03mm²-0,34mm²)
Locator für digitale Crimpzange Best.-Nr.: C0.265.00

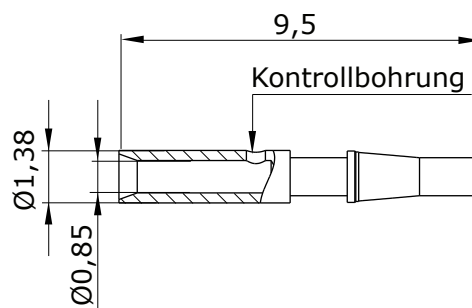

Hauptabmessungen

Kontaktbuchse



for: 723 htec
740 htec



order code.: 60.278.11

Electrical Data

transfer rate 100Mbit (cat5)
contact resistance < 15 mOhm

Material

contact brass, gold plated

Termination


kind of termination crimp
cross-section 0.03 - 0.34mm²
stripping length 4 mm
wire diameter max. Ø1,6 mm

Mechanical Data

mating cycles 500

Tools (not part of product contents)

digital crimping tool order code: C0.235.00
for 0,6mm contacts (0,03mm²-0,34mm²)
locator for digital crimping tool order code: C0.265.00

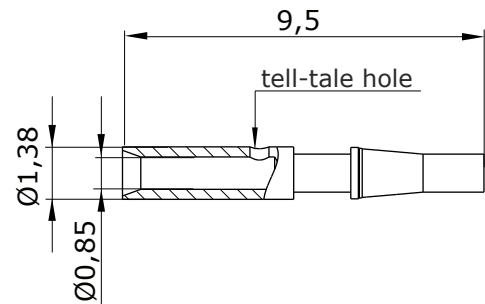

Main Dimensions
contact socket

