

**Einsatzbereich: 923 Einbaudose  
923 Winkeleinbaudose  
923 Kupplung 9-polig**

**Best.-Nr.: 61.193.11**



## Elektrische Werte

\* Bemessungsstrom bis 30 A  
Durchgangswiderstand < 3 mOhm

## Werkstoff

Kontakt Messing, vergoldet

## Anschluss


Anschlussart/-bereich Crimp/ 0,35 - 2,5mm  
Abisolierlänge 7 mm  
Crimpeinstellungen sind individuell zu wählen

## Mechanische Werte

Steckzyklen 500

## Werkzeuge (nicht im Lieferumfang enthalten)

digitale Crimpzange Best.-Nr.: C0.236.00  
analoge Crimpzange Best.-Nr.: C0.201.00  
(Positioniereinsatz für 2 mm Kontakte Best.-Nr.: C0.004.00)

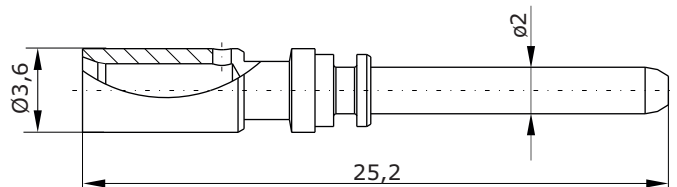

## Hauptabmessungen

Kontaktstift





# Contact pin ø2mm

application area: 923 Receptagle  
923 Receptagle angled  
923 Extension 9-pin  
order code: 61.193.11

## Electrical data

\*rated current up to 30 A  
contact resistance < 3 mOhm

## Material

contact brass, gold plated

## Termination


cross-section crimp/ 0,35 - 2,5mm<sup>2</sup>  
stripping length 7 mm  
crimp settings select individually

## Mechanical data

mating cycles 500

## Tools (not part of product contents)

digital crimping tool order code: C0.236.00  
analog crimping tool order code: C0.201.00  
(Positioner for 2 mm contacts order code: C0.004.00)

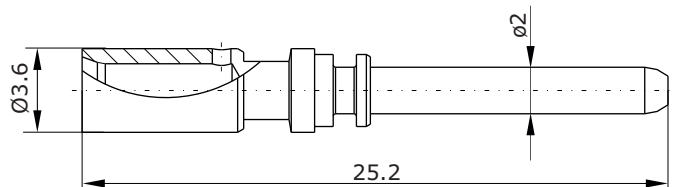

## Main dimension

contact pin

