



# LogiLink®

Solar Power Bank 10.000 mAh  
with PD and QC Fast Charging

Art. No.: PA0273

## Your Adventure Travel Companion

The Solar Charging Power Bank is perfect for fast charging your devices outdoors. The solar panel absorbs natural light from the sun and converts it into energy, making this charger the ideal companion to any camping, hiking or fishing trip.



10.000  
mAh

Dual  
Inputs/Outputs

18W  
Inputs/Outputs

Solar  
Power

QC3.0  
Fast Charging

PD2.0  
Fast Charging

Wide  
compatibility

Flash  
Light

  
IP44  
Waterproof



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



PA0273



4 052792 066456


Made in China

## Convenient Simultaneous Charging

Fast charging of two devices with USB-C PD 2.0 and USB-A QC 3.0 ports at the same time, delivers up to 18 W for your power hungry devices.

## Fast Charging Inputs

Quickly charge your power bank with the USB-C or Micro-B port.

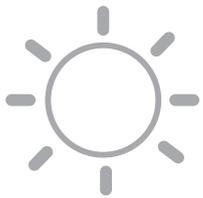

## Get Power When You're in a Jam

Solar charging function for emergency use or as an auxiliary power source.



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



PA0273



4 052792 066456

Made in China



### Handy Emergency Flashlight

Built in two color LED flashlight with 3 modes: Steady, SOS and Strobe. SOS mode can be used as an emergency light in the dark or to light up an entire room.

### Multiple Protection

Extremely safe and reliable, these power banks come with overcurrent, overvoltage, overheating and short circuit protection.



Conveniently put it on anywhere with a stand.



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



PA0273



4 052792 066456

Made in China

## Specifications:

Battery Capacity	10.000 mAh
Battery Cell	3,7 V lithium battery
Input Power (Max.)	Micro USB : 5 V/2 A, 9 V/2 A (18 W) USB-C: 5 V/3 A, 9 V/ 2 A, 12 V/ 1,5 A (18 W)  *Total input 18 W max.
Solar Panel Input Power	5 V/0,25 A
Power Input Interface	USB-C & Micro-B
Output Power (Max.)	USB-A :5 V/3 A, 9 V/ 2 A, 12 V/ 1,5 A (18 W) USB-C :5 V/3 A, 9 V/ 2 A, 12 V/ 1,5 A (18 W)  *Total output 18 W max.
Power Output Interface:	USB-C & USB-A
Housing Material	ABS
LED Indicator	Yes
Dimension	16,3x8,4x1,8 cm
Weight (g)	285 g
Smart Fast Charging	Yes
Quick Charging	QC 3.0
Power Delivery	PD 2.0
Charging Cable Type	2-in-1 USB-C & Micro-B charging cable
Cable Length (cm)	30 cm
Solar Charging	Yes
Flashlight	LED flashlight 18 pcs white LED and 18 pcs orange LED
Waterproof	IP44
Operating Temperature	-10–45°C
Operating Humidity	40–60% RH (no condensation)
Storage Temperature	0–40°C
Storage Humidity	40–60% RH (no condensation)

## Package Contents:

- » 1x 10.000 mAh Solar Power Bank
- » 1x 2 in 1 USB-C & Micro-B Cable
- » 1x User Manual

## Package Information:

- » Packing Dimension: 175 x 90 x 25 mm
- » Packing Weight: 0,335 kg
- » Carton Dimension: 380 x 270 x 190 mm
- » Carton Q'ty: 40 pcs
- » Carton Weight: 14,2 kg



\*The specifications and pictures are subject to change without prior notice.  
\*All trade names referenced are the registered trademarks of their respective owners.



Made in China