

Technical data sheet

EMC Accessories · Grounding Device

Grounding strip, copper braiding, tin-plated
Single wire Cu ETP UNI 5649-71, similar to DIN 72333



Identification

Type	EMVMB 10/200/6
Part No.	346112.0010

Product version

Datasheet version	01
-------------------	----

Technical data

Tape thickness	1.5 mm
Drilling diameter	6.5 mm
Sleeve length	20 mm
Length	200 mm
Width	15 mm
Cross-section surface	10 mm ²
Ampacity	75 A

Connecting lead

Description	both ends drilled, cold pressed
-------------	---------------------------------

Construction

Cable construction	individual strands braided cross-section rectangular
Wire conductors	0.15 mm ²

United Kingdom: LÜTZE Ltd.

Unit 3, Sandy Hill Park
Sandy Way, Amington • GB-Tamworth, Staffs B77 4DU
Tel. +44 (0)1827 31333-0 • Fax +44 (0)1827 31333-2
www.lutze.com • sales.gb@lutze.co.uk

Germany: Friedrich Lütze GmbH

Postfach 12 24 (PLZ 71366) • Bruckwiesenstraße 17-19 • D-71384 Weinstadt
Tel. +49 (0)7151 6053-0 • Fax +49 (0)7151 6053-277(-288)
www.luetze.de • info@luetze.de

22.09.2023 • Subject to technical modification

Part No. [346112.0010](#) • Datasheet version: 01

page 1 of 4



SYSTEMATIC TECHNOLOGY

Technical data sheet

EMC Accessories · Grounding Device

General

Operation temperature range	+5 °C ... +105 °C
Storage temperature range	-30 °C ... +90 °C
Weight/unit	0.18 kg
Weight	0.1 kg/m
PU (units)	10

Certifications/Standards

Certifications	cULus
----------------	-------


Notes and Comments

Comments	D = hole diameter A = sleeve length B = width L = distance of hole Other lengths are available upon request
----------	--

Explanation

A	22 mm
B	12 mm
D	6.5 mm
L	200 mm

Dimensions

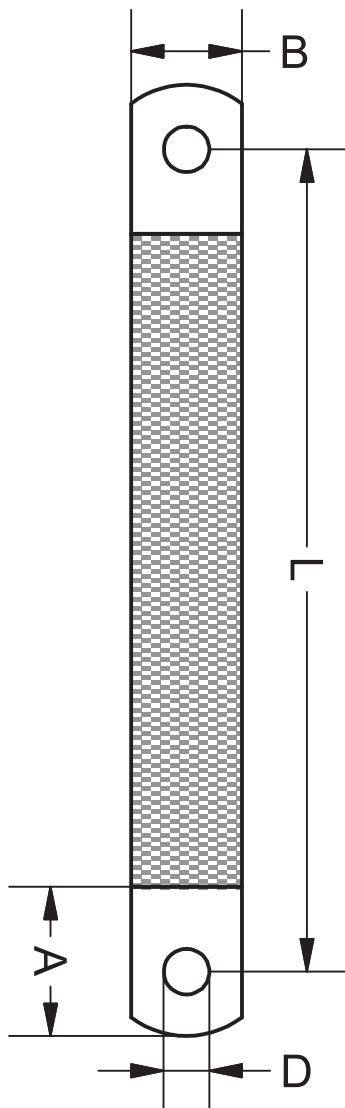

Use

