




Baton Turbo

Your Best Backup

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
1,000 lumens	50 days	510 meters

*This information is for market reference only. Please do not make it public.



Black



OD Green

MARKET APPLICATIONS



Camping
Hiking
Wildlife Spotting
Cave Exploration
Home Use

UPC :

6975498003601
6975498003885 (OD Green)

DESCRIPTION



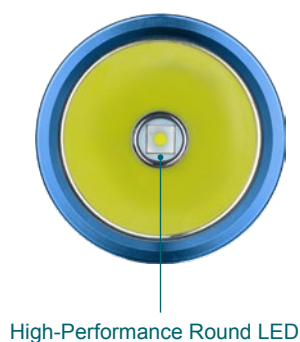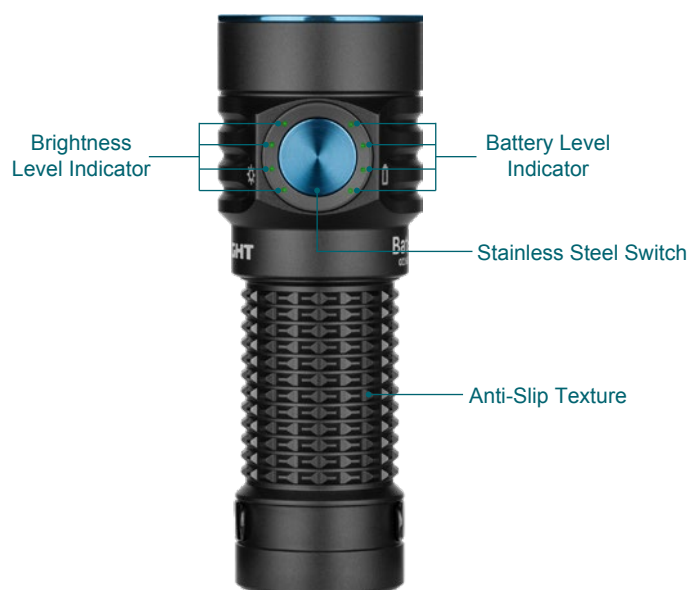


With a powerful 510m beam, extended runtimes and multiple power sources, the Baton Turbo is the perfect backup for outdoor adventures, home use, and emergencies. At just 3.2 inches and 3.2 ounces, this palm-sized light delivers a strikingly bright beam with a sharp spot and wide spill from its coin-sized bezel. Slip it in your pocket, clip it to your hat, or attach the lanyard to carry it effortlessly. Keep the light as your backup to banish darkness whenever needed.



FEATURES

- **Long-Range EDC:** The palm-sized light projects a 510-meter beam from a coin-sized bezel, making it an ideal backup for extended visibility.
- **Flexible Power Sources:** Powered by the included rechargeable 18350 battery, with the flexibility to use a single-use CR123A battery for added convenience (with limited brightness).
- **Extended Runtimes:** A 1.5-hour charge provides 50 days of continuous Moonlight mode visibility for worry-free use.
- **Safety Switch and Intuitive Dashboard:** Recessed switch for safe carry, with a sleek dashboard displaying brightness and power levels at a glance.
- **Easy, Versatile Carry:** The custom two-way clip enables deep bezel down pocket carry. You can also clip it to your hat, or attach the included lanyard to your wrist.
- **Your Dependable Backup for Every Situation:** Keep this compact light at home, in your vehicle, or with your outdoor gear to always be prepared for any dark situation.

OUTPUT

SPECIFICATIONS	Turbo	High	Medium	Low	Moonlight
	1,000±300 lumens	300±60 lumens	60 lumens	10 lumens	< 1 lumen
	2.5+92 minutes	103+18 minutes	10 hours	60 hours	50 days
	510 meters	275 meters	120 meters	48 meters	5 meters
	65,025 cd	N/A			
	13 Hz at 1,000 lumens				

* Note: All data above are test results according to ANSI/NEMA FL 1-2019 standards.

WATERPROOF IPX8



DROP TEST



COMPLIANCE



olight.com © Olight 08/26/24 V1
Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.

LIGHT SOURCE

High Performance Round LED
Color Temperature: 6500K–7500K

DIMENSIONS

Length: 3.22 in / 81.7 mm
Body Diameter: 0.94 in / 24 mm
Head Diameter: 1.14 in / 29 mm

WEIGHT

3.21 oz / 91g (Including Battery)

BODY MATERIAL

Aluminum Alloy

POWERED BY

- Customized 3.6V 1100mAh 18350 Rechargeable Lithium-ion Battery (Included)
- Single-Use CR123A Battery (Optional)
(Note: Requires the included sleeve; brightness will be limited.)

WARRANTY

Lifetime Warranty in Australia, China, France, Germany and the USA.
5-Year Warranty in other countries and regions.

IN THE BOX

Baton Turbo (battery included) x 1
MCC-1A x 1
Pouch x 1
Lanyard x 1
Sleeve (for CR123A Battery) x 1
User Manual x 1

OPTIONAL ACCESSORY

MCC3 Magnetic Charging Cable