
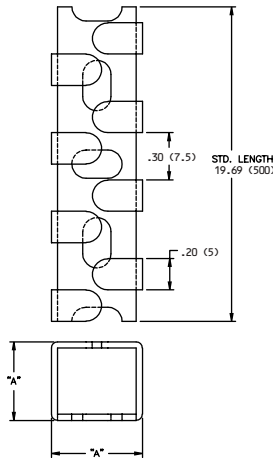
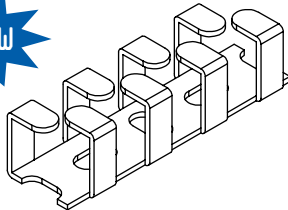


RX

Richflex Flexible Channel

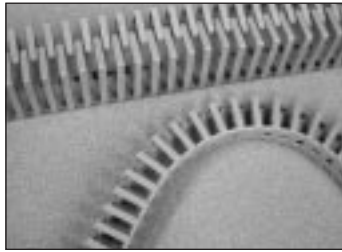

Features


- Available with or without adhesive

Material: Polypropylene • Color: Grey				
Part No.	Ext. Dim. "A" x "A" in (mm)	Type	Int. Section in ² (mm ²)	Standard Packing (pcs)
RX1313-0	.492 x .492 (12.5 x 12.5)	VMHDY40	.171 (110)	112
RX1313-4		AMHD40		
RX1616-0	.630 x .630 (16 x 16)	VMHDY40	.287 (185)	84
RX1616-4		AMHD40		
RX2020-0	.787 x .787 (20 x 20)	VMHDY40	.496 (320)	112
RX2020-4		AMHD40		
RX2525-0	.984 x .984 (25 x 25)	VMHDY40	.775 (500)	70
RX2525-4		AMHD40		
RX3030-0	1.181 x 1.181 (30 x 30)	VMHDY40	1.116 (720)	50
RX3030-4		AMHD40		
RX4040-0	1.575 x 1.575 (40 x 40)	VMHDY40	2.046 (1320)	50
RX4040-4		AMHD40		
RX5050-0	1.969 x 1.969 (50 x 50)	VMHDY40	3.162 (2040)	32
RX5050-4		AMHD40		

Part Type Code: A - Adhesive Backing; D - UL94V2; H - Halogen Presence Insignificant (<70%); M - Polypropylene; V - Screw Mount; 40 - Gray RAL7040.


SRWD/SRWDN

Slotted Richco Wiring Duct

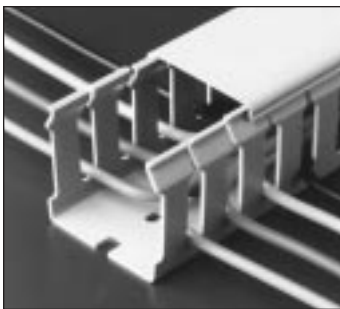


Features


- Holds breakout wires while providing flexibility for adding or removing wires later
- Simply deflect the plastic fingers to insert or remove wires
- Non-slip cover is easy to use and included with base
- Parts are 6-1/2' (1.98m) long
- Material is serviceable from -40°F – 140°F (-40°C – 60°C)
- Fingers are scored for easy break out

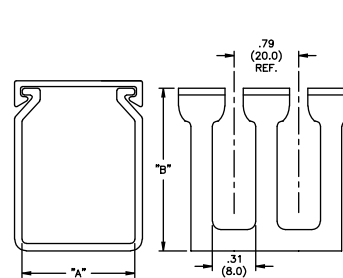


SRWD-OPEN SLOT

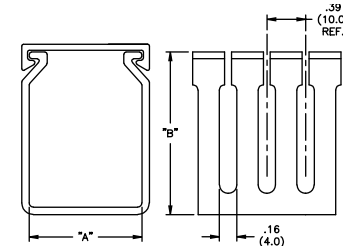

SRWDN-NARROW SLOT

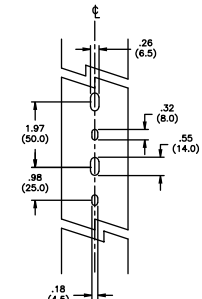

Mounting Style #1

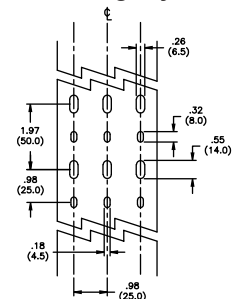

Mounting Style #2

Material: PVC (UL #E161178) (CSA #LR40012-7)
Color: Gray

Parts also available in White, Black and Blue by special order. To order, add suffix W for White, BL for Blue, and B for Black

Material: PVC (UL #E161178) (CSA #LR40012-7)
Color: Gray

Parts also available in White, Black and Blue by special order. To order, add suffix W for White, BL for Blue, and B for Black