

D-Sub / HD D-Sub Steckverbinderhauben zur Kabelmontage IP67 D-Sub / HD D-Sub Cable Assembly Connector Hoods IP67


Technische Daten / Technical Data

Material: Thermoplast, UL94 V-O
Material: Thermoplastic, UL94 V-O
Temperaturbereich: -20°C ... +80°C
Temperature Range: -20°C ... +80°C




© W+P PRODUCTS


D-Sub-Verbinder im Hauptkatalog:
D-SUB Connector in the main
connector catalogue:
100 105 108 112 115 116

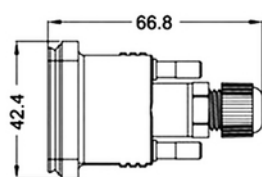

09/15 Pins

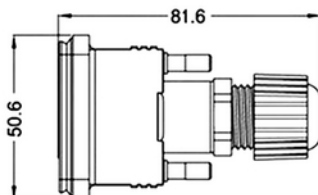

15/26 Pins

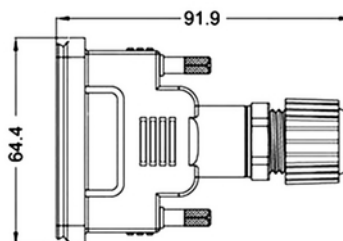

25/44 Pins

Series

W307

Size*

15

IP Class

7

09 D-SUB 09 / HD D-SUB 15, Outer Diameter Ø 3,5 - 7,0 mm
15 D-SUB 15 / HD D-SUB 26, Outer Diameter Ø 6,0 - 10,0 mm
25 D-SUB 25 / HD D-SUB 44, Outer Diameter Ø 6,0 - 10,0 mm

7 IP67

* Dies ist ein **Bestellbeispiel** -
bitte durch Ihre Spezifikationen ersetzen.
* This is an **order example** -
please replace by your specifications.