

PRODUCT DATASHEET



Product	AGFAPHOTO Lithium Battery	
Type/Size	CR 2	


An Gut Nazareth 18 a
52353 Düren, Germany
Tel. +49(0)2421/392071
Fax +49(0)2421/391453
service@german-battery.de
www.german-battery.de

Specifications

Chemical system	lithium-manganese dioxide	
Dimensions	Diameter:	15.3 - 15.6 mm
	Height:	26.9 - 27.2 mm
Weight (approx.)	11 g	
Packaging	1 battery in blister-pack with punch hole	
Nominal voltage	3.0 V	
Nominal capacity	750 mAh	
Standard discharge current	10 mA	
Continuous discharge current (max.)	800 mA	
Pulse discharge current (max.)	1,500 mA	
Temperature range	-40 up to 70 °C	

Typical discharge characteristics

Discharge characteristics vs. temperature

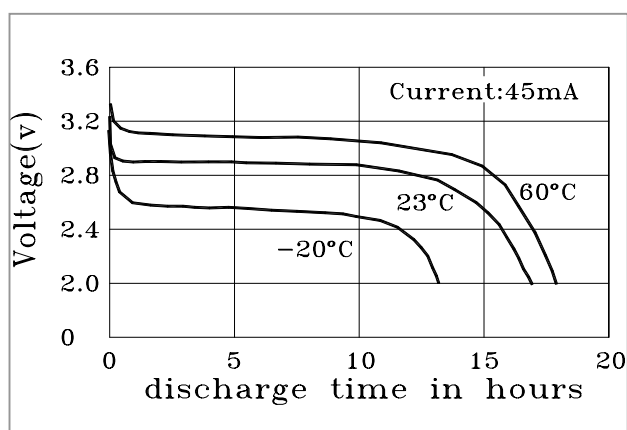

Pulse discharge characteristics

