
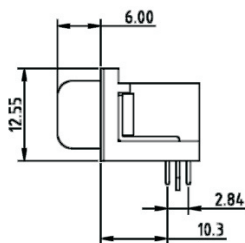


Artikel-Nr.:1234736, 1234737, 1234738

Bez.D-Sub-Stecker 9 pol (bzw. 15 pol, 25 pol), Printanschluss 90°:

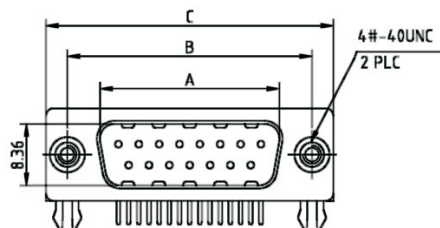

NO. OF CONTACTS:

09, 15, 25, 37

WITH ASSEMBLED HEX SCREW BOLTS

Note:

No.	A	B	C
09	16.92	24.99	30.81
15	25.25	33.32	39.14
25	38.96	47.04	53.04
37	55.42	63.50	69.32



ELECTRICAL CHARACTERISTICS

Contact Current Rating:3Amperes.
Dielectric Withstanding Voltage:AC 500V at sea level.
Insulation Resistance:1000Megohms Min.
Contact Resistance:30Milliohms Max.
Operation Temperature : -55°C to +105°C.

Material

Contact :Copper Alloy.
Insulator:PBT. [Select PA6T /LCP /PA9T]
Shell: SPCC.
X1 Z-Piece: Fe.
Screw: Copper Alloy.
Rivet: Copper Alloy or Zinc.

Recommend PCB Layout

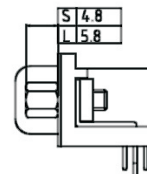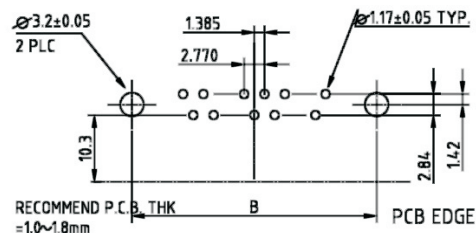

www.bkl-electronic.de

Technische Änderungen vorbehalten. Ausführungen können variieren. Sollten Sie ein Muster benötigen kontaktieren Sie uns bitte.

BKL-ELECTRONIC Kreimendahl GmbH • Märkenstück 14 • 58509 Lüdenscheid

Tel: +49 (0)2351-3621-0 • Fax: +49 (0)2351-3621-29 • info@bkl-electronic.de

