

CLIFF

3.5mm VERTICAL JACK SOCKET


Stereo switched 3.5mm jack socket. Vertical PCB mounting. Supplied with ring nut or hex nut.



**FC681375V
WITH RING NUT**



**FC681375VH
WITH HEX NUT**

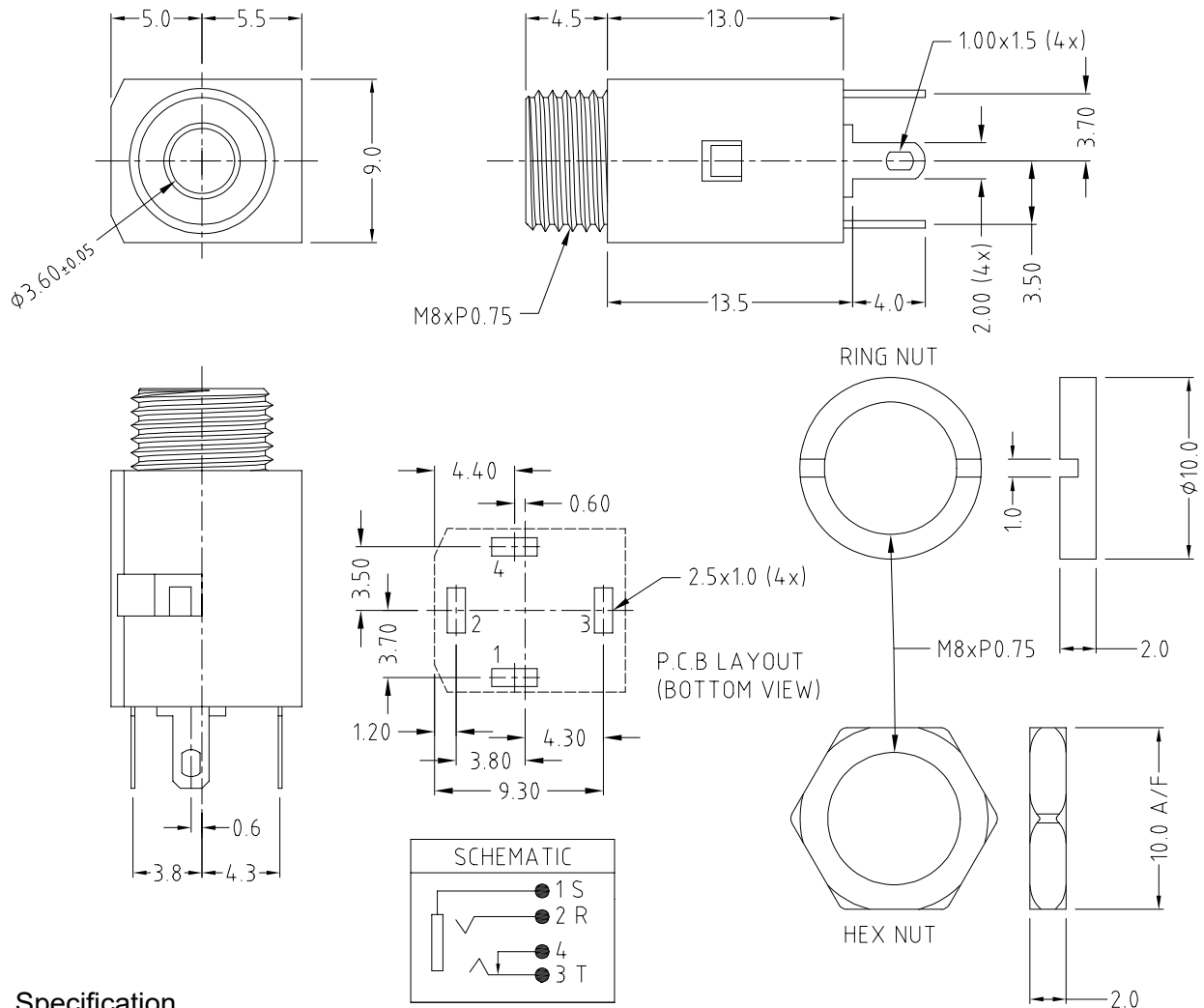

Specification

Contact Resistance: 30m Ω max.

Insulation Resistance: 100M Ω min. at DC 500V

Dielectric Withstand Voltage: AC 500V for 1 minute