

Date 01.12.2010

RRJVA_RJ45

Technical Data

Type reference:
Description:
Approvals:
Protection degree:
Jack:


RRJVA_RJ45
RJ45 jack
CE
IP65
RJ45 8/8

Cable:

Cat 5
Length 0.6 m
Connector RJ45 8/8

Mounting diameter:
Operating temperature max.:
Storage temperature max:

22.3mm
-20°C ... 60°C
-25°C ... 80°C

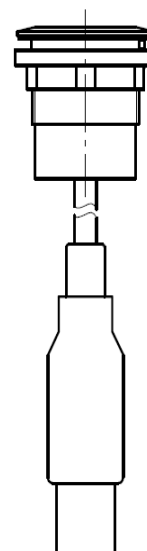

- Subject to alterations -