


Model	BSH-04M	Flashing LED Module	Category	Gifts
-------	---------	---------------------	----------	-------

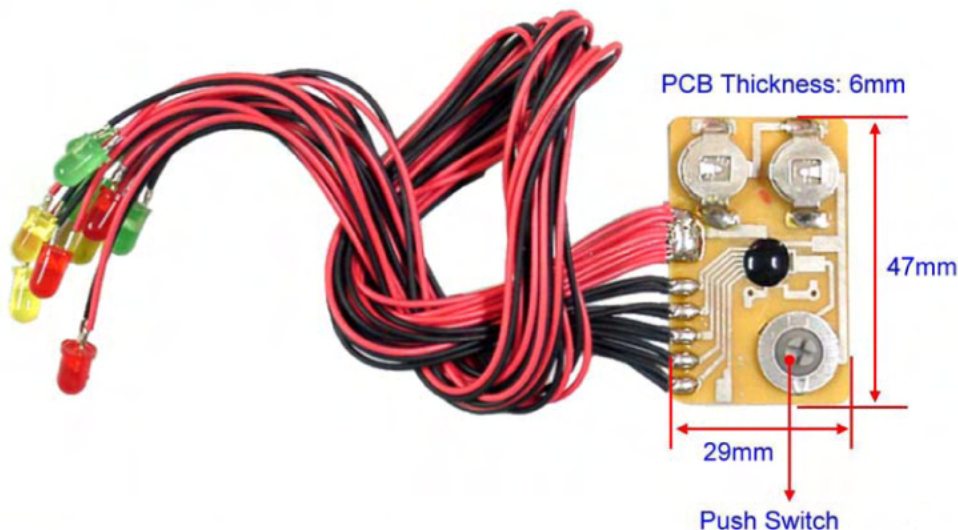

Feature	<ul style="list-style-type: none"> ● Ideal to apply on to decorative product for celebrations. ● Total of 6 outputs and 10 LED connectors ● Choice of power on/off switch or one shot function (each activation flashes the LED for 15 seconds) 			
Operation	<ul style="list-style-type: none"> ● One shot function: each activation flashes the LED for 15 seconds. 			
IC Function	Flashing LED IC			
Operation Current	□ 25 mA	Play time	4 hours continue on or 1,800 times (15 seconds flashing/activation)	
Standby Current	□ 2 uA	Shelf Life		
Input / Switch	Push switch (On/off or activation)			
LED / EL Brightness	□ 50 lux @ 10cm Distance (Surrounding at □ 0lux)	Color & Quantity	5Φ LED x10 (any yellow, red, green color combination)	
Sound Output	N/A	Speaker Size / Type	N/A	
Operation Voltage	3V	Battery Type	AG10 (LR1130) x2	
Size (WxHxD)	PCB size: 47 x 29 x 6mm		Material	
Weight	15.2g (Battery included)		Packing	
Spec Revision:	2006-03-09	Approval	Barry Hsieh	Engineer Jane Huang