


Datasheet

Item no. 1565137, 1566730 & 1572130

V1_04092018_01_en

Fully Insulated Female Disconnecter Series

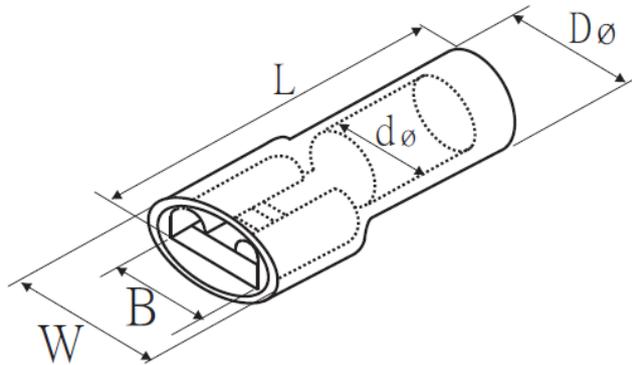

Operating Temperature: 75°C max.

Material
Terminal : Copper
Insulation : PVC
Plating : TIN

WIRE RANGE mm ² / AWG	B/N	DIMENSION						COLOR
		TAB (mm)	W (mm)	B (mm)	Dø (mm)	dø (mm)	L (mm)	
0.5~1.5mm ² 22~16 AWG	1565137	0.8×6.35	9.3	6.5	3.8	1.7	23	RED
1.5~2.5mm ² 16~14 AWG	1566730	0.8×6.35	9.3	6.5	6	2.6	23	BLUE
4~6mm ² 12~10 AWG	1572130	0.8×6.35	9.3	6.5	7	3.6	25	YELLOW

Dimension: ± 0.3 mm