


Data Sheet

Metal Cable Gland – M series

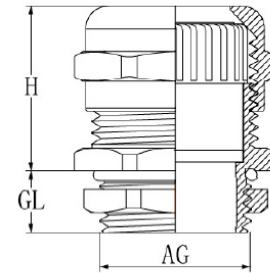

Material: Nickel-plated brass
 Claw: PA66 (Nylon), UL94-V2
 Hermetic seal: NBR, Silicone rubber
 O-Ring: NBR, Silicone rubber
 Protection degree: IP68-10 bar
 Temperature: Static state: -40 °C to 100 °C, Short time to 120 °C;
 Dynamic state: -20 °C to 80 °C, Short time to 100 °C

Unit: mm

Item no.	Item	Ø Cable range	GL Thread Length	AG Thread O.D.	H Joint Length	Spanner size
2575704	M8 x 1	2 - 5	5	8	13.5	12
2575705	M12 x 1.5	3 - 6.5	6.5	10	17	14
2575706	M16 x 1.5	4 - 8	8	16	19	18
2575707	M18 x 1.5	5 - 10	8	18	20	20
2575708	M20 x 1.5	6 - 12	8	20	21	22
2575709	M22 x 1.5	10 - 14	8	22	22	24
2575710	M25 x 1.5	10 - 14	9	25	22	24/27
2575711	M30 x 2	13-18	9	30	27	30/32
2575712	M32 x 1.5	15-22	10	32	29	35
2575713	M40 x 1.5	18-25	11	40	31	40/45
2575714	M50 x 1.5	32-38	13	50	37	57/55
2575715	M63 x 1.5	37-44	14	63	38	64/68
2575716	M75 x 2	42-52	16	75	44	78/80