


Fully Insulated Female Spade connector Flat Receptacle, 6.38 x 0.8 mm Tab Size 0.5 mm² - 1.5 mm² (AWG22-18), PVC, Red 100pcs

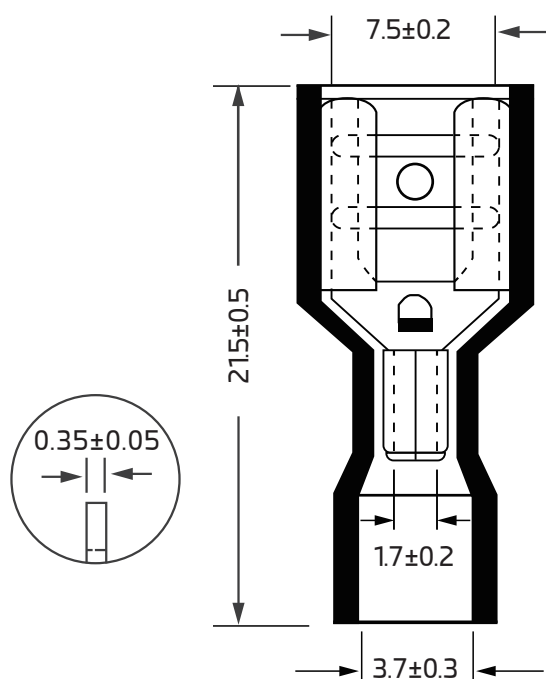

Specification

Connector type	: Spade Receptacle
Termination method	: Crimp
Insulation type	: Fully insulation
Insulation material	: PVC
Insulator color	: Red
Terminal material	: Brass
Terminal plating	: Tin
Terminal thickness	: 0.35 mm
Wire guide	: AWG 22-18
Wire cross section	: 0.5 - 1.5 mm ²
Tab Size	: 6.3 x 0.8 mm
Rated current	: 10A max.
Rated temperature	: -10°C ~ 75°C