
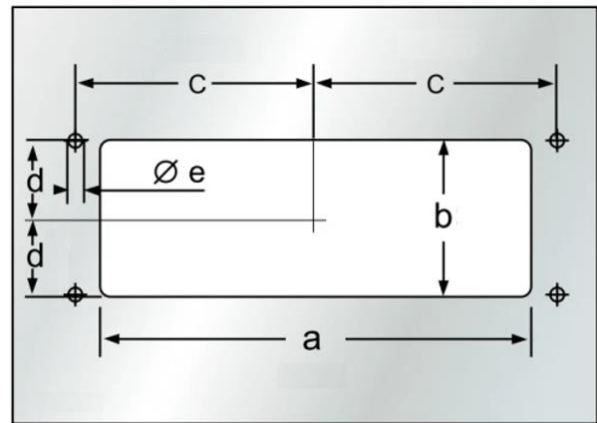


## Data Sheet

### Cable Entry System TC-KDL series

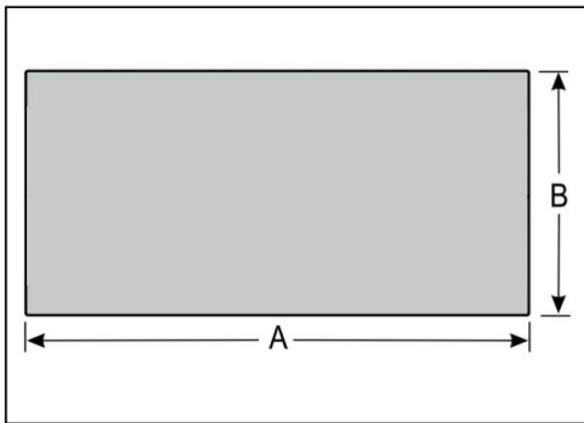

Item No.	No. of opening s	A (mm)	B (mm)	Installation height	a (mm)	b (mm)	c (mm)	d (mm)	e (mm)
2998147	4	116	58	10	86	36	51.5	16	5.5
2998148	5	146	58	10	112	36	65	16	5.5
2998149	10	146	90	10	112	55	65	32	5.5
2998150	15	146	122	10	112	96	65	48	5.5

- Material: PA
- Colour: Black
- UL 94-V0
- Protection degree: IP54
- Temperature range: -40 – 80 °C

## Data Sheet

---

### Cable Entry Grommets – TC-KDT series



Item No.	Cable Diameter (∅) mm		Item No.	Cable Diameter (∅) mm
2998151	3 - 4		2998158	10 - 11
2998152	4 - 5		2998159	11 - 12
2998253	5 - 6		2998160	12 - 13
2998154	6 - 7		2998161	13 - 14
2998155	7 - 8		2998162	14 - 15
2998256	8 - 9		2998163	15 - 16
2998157	9 - 10		2998164	Dummy

11

- Material: TPR
- Colour: Black
- Protection degree: IP54
- Grommet diameter: 3 – 16 mm
- Temperature range: -40 – 80 °C