
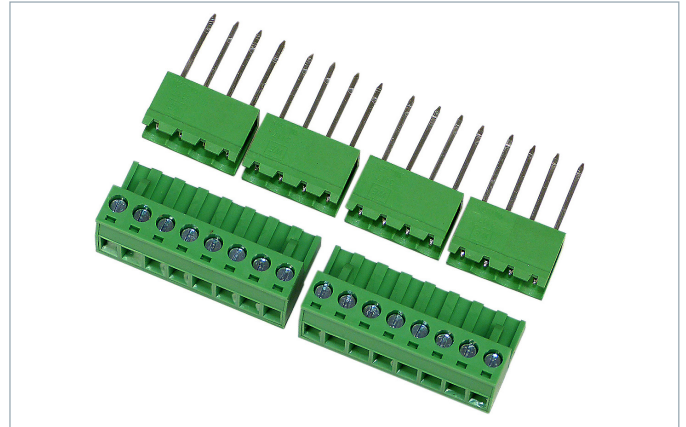


Terminal Connector Kit

R&S[®]HZP20

R&S[®]HZP40

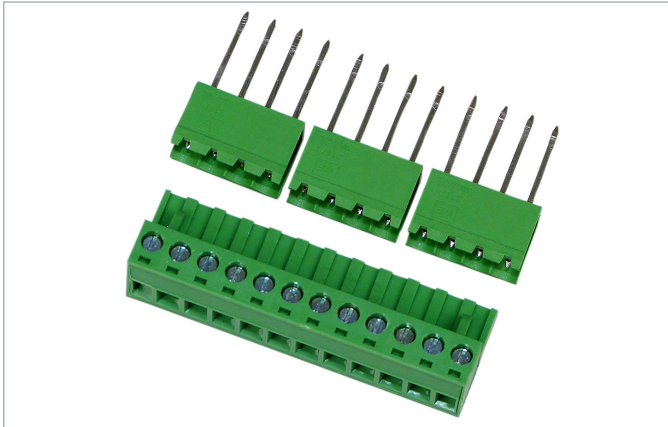

R&S[®]HZP20

for power supplies HMP2020 and HMP2030

Items per unit: 1 kit

RoHS conform

R&S material number: 5800.3215.02

HAMEG item number: 27-P020-RS00

R&S[®]HZP40


for power supplies HMP4030 and HMP4040

Items per unit: 1 kit


RoHS conform

R&S material number: 5800.3221.02

HAMEG item number: 27-P040-RS00

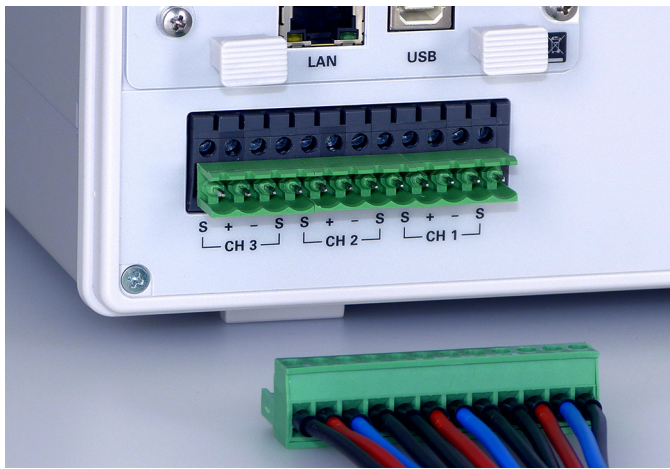

R&S®HWP20 connected to HMP2030

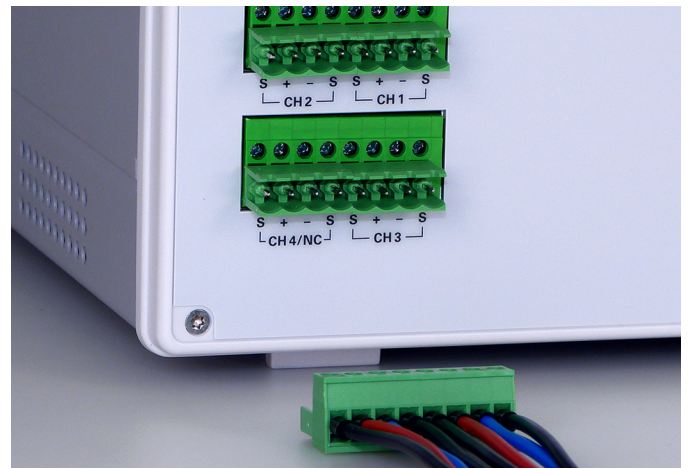

R&S®HWP40 connected to HMP4040

Terminal Connector Kit

R&S®HWP20

R&S®HWP40

Technical Data

Material:	
Male contact pin:	Copper, Tin plated
Terminals (housing):	Thermoplastic (UL94 V-0)
Electrical:	cULus / VDE
Voltage rating:	300V / 300V
Current rating:	20A / 20A
Withstanding Voltage:	1.6kV / 2.5kV
Operating temperature:	-40°C to +115°C

www.hameg.com
value.rohde-schwarz.com

HAMEG Instruments GmbH
 Industriestr. 6 | 63533 Mainhausen | Germany | Tel +49(0)61828000

R&S® is a registered trademark of Rohde & Schwarz GmbH & Co. KG
 HAMEG Instruments® is a registered trademark of HAMEG
 Instruments GmbH; Trade names are trademarks of the owners
 09/2014 | © HAMEG Instruments GmbH
 Subject to change without notice