

IE-PS-V01M-2LC-MM-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (Ethernet/IP), RJ45 metal insert incl.
LC insert

General ordering data

Version	FO connector, Variant 1, LC-Duplex multi-mode, with kink prevention, IP67
Order No.	1963230000
Type	IE-PS-V01M-2LC-MM-BP
GTIN (EAN)	4032248651702
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2025-04-08T00:00:00+02:00

IE-PS-V01M-2LC-MM-BP

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	133.7 mm	Depth (inches)	5.2638 inch
Height	30 mm	Height (inches)	1.1811 inch
Width	30 mm	Width (inches)	1.1811 inch
Net weight	14.2 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	e5bbf197-73b5-420b-90c0-0173b7b3b6b7

General data

Description of article	Variant 1, LC-Duplex multi-mode, with kink prevention	Colour	Miscellaneous
Housing main material	Zinc diecast	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Protection degree	IP67
Plugging cycles	500	Fibre type	Multimode
Insertion loss	0.5 dB singlemode, 0.4 dB multimode	Connection 1	LC
Connection 2	gluing, crimping, polishing	Housing material, insert	PBT, Zinc diecast
Return loss (attenuation)	40 dB singlemode; 30 dB multimode		

General standards


Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-20
--------------------	---

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22
ECLASS 13.0	19-17-01-22	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		

Drawings

 Dimensioned drawing



IE-PS-V01M-2LC-MM-BP

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Dust caps




For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V01P	Version
Order No.	1965690000	Plug housing protective cap
GTIN (EAN)	4032248653911	
Qty.	10 ST	

Blank

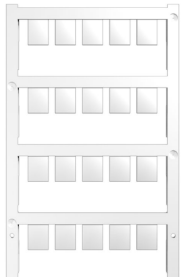

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive
GTIN (EAN)	4032248402731	
Qty.	200 ST	