

WIL-F-240

Weidmüller Interface GmbH & Co. KG


Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

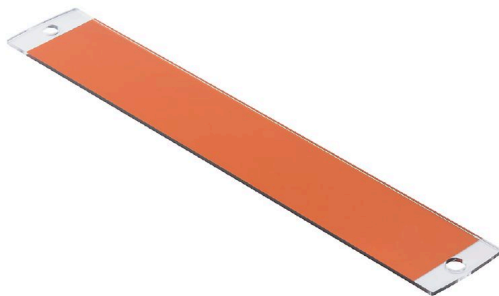

UV filter for additional screwing to the Weidmüller Industry Light.

General ordering data

Order No.	2799050000
Type	WIL-F-240
GTIN (EAN)	4064675259084
Qty.	4 items

WIL-F-240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	38.5 mm	Depth (inches)	1.5157 inch
Height	2.2 mm	Height (inches)	0.0866 inch
Width	240 mm	Width (inches)	9.4488 inch
Net weight	34.5 g		

Temperatures

Operating temperature	-
-----------------------	---


Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Classifications

ETIM 6.0	EC002558	ETIM 7.0	EC002558
ETIM 8.0	EC002558	ETIM 9.0	EC002558
ETIM 10.0	EC002558	ECLASS 9.1	27-11-11-25
ECLASS 10.0	27-11-11-25	ECLASS 11.0	27-11-11-25
ECLASS 12.0	27-11-11-25	ECLASS 13.0	27-11-11-25
ECLASS 14.0	27-11-11-25	ECLASS 15.0	27-11-11-25

 Drawings



WIL-F-240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Counterpart

Housing length 240 mm



240 mm

The WIL-LED lights family: Only 8mm (9.4mm with magnet) high LED lamp for 24V DC with very high luminous efficacy and high lifespan (greater 60 000h). Very robust construction, by full potting and metal housing - waterproof (IP67). Due to its 6500K light color (daylight) suitable for the various applications. Optionally easily connectable with M12 connection. Due to the low power consumption, a small enough power supply with 24V for operation.

General ordering data

Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2436210000	
GTIN (EAN)	4050118448306	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527880000	
GTIN (EAN)	4050118538762	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527890000	
GTIN (EAN)	4050118538670	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527900000	
GTIN (EAN)	4050118538687	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527910000	
GTIN (EAN)	4050118538694	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527950000	
GTIN (EAN)	4050118538939	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527990000	
GTIN (EAN)	4050118538977	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527920000	
GTIN (EAN)	4050118538908	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527960000	
GTIN (EAN)	4050118538946	
Qty.	1 ST	
Type	WIL-LWXXXX-6500D024-240...	Version
Order No.	2527930000	
GTIN (EAN)	4050118538915	
Qty.	1 ST	

WIL-F-240

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Counterpart

Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2527940000
GTIN (EAN)	4050118538922
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2527970000
GTIN (EAN)	4050118538953
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2527980000
GTIN (EAN)	4050118538960
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2669240000
GTIN (EAN)	4050118682601
Qty.	1 ST

Housing length 145 mm



145 mm

The WIL-LED lights family: Only 8mm (9.4mm with magnet) high LED lamp for 24V DC with very high luminous efficacy and high lifespan (greater 60 000h). Very robust construction, by full potting and metal housing - waterproof (IP67). Due to its 6500K light color (daylight) suitable for the various applications. Optionally easily connectable with M12 connection. Due to the low power consumption, a small enough power supply with 24V for operation.

General ordering data

Type	WIL-LWXXXX-6500D024-145... Version
Order No.	2669230000
GTIN (EAN)	4050118682618
Qty.	1 ST

Housing length 240 mm



240 mm

The WIL-LED lights family: Only 8mm (9.4mm with magnet) high LED lamp for 24V DC with very high luminous efficacy and high lifespan (greater 60 000h). Very robust construction, by full potting and metal housing - waterproof (IP67). Due to its 6500K light color (daylight) suitable for the various applications. Optionally easily connectable with M12 connection. Due to the low power consumption, a small enough power supply with 24V for operation.

General ordering data

Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2528030000
GTIN (EAN)	4050118539011
Qty.	1 ST

WIL-F-240**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Counterpart

Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2528020000
GTIN (EAN)	4050118539004
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2528010000
GTIN (EAN)	4050118538991
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2528000000
GTIN (EAN)	4050118538984
Qty.	1 ST
Type	WIL-LWXXXX-6500D024-240... Version
Order No.	2576960000
GTIN (EAN)	4050118592863
Qty.	1 ST
Type	WIL-LWXXXX-4000D024-240... Version
Order No.	2617810000
GTIN (EAN)	4050118649185
Qty.	1 ST
Type	WIL-LWXXXX-4000D024-240... Version
Order No.	2770730000
GTIN (EAN)	4064675030799
Qty.	1 ST
Type	WIL-LWXXXX-4000D024-240... Version
Order No.	2732910000
GTIN (EAN)	4050118811797
Qty.	1 ST
Type	WIL-LWXXXX-2700D024-240... Version
Order No.	2633830000
GTIN (EAN)	4050118648959
Qty.	1 ST
Type	WIL-LWXXXX-2700D024-240... Version
Order No.	2680950000
GTIN (EAN)	4050118694710
Qty.	1 ST