


PAC-UNIV-HE16-F-3M

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

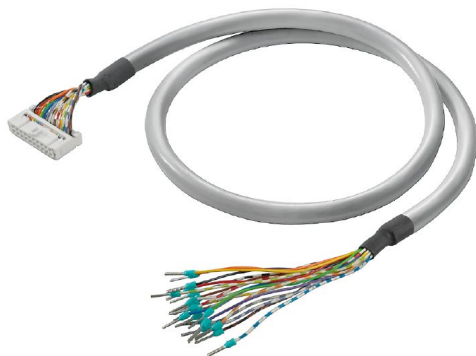

Similar to illustration

General ordering data

Version	Pre-assembled cable, PAC
Order No.	1349770030
Type	PAC-UNIV-HE16-F-3M
GTIN (EAN)	4032248176144
Qty.	1 items

PAC-UNIV-HE16-F-3M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Net weight	214 g
------------	-------

Temperatures

Storage temperature	-10...60 °C	Operating temperature	-10...50 °C
---------------------	-------------	-----------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	No SVHC above 0.1 wt%

General Data

Cable length	3 m	Suitable for	Digital signals
Basic material	PVC	Cable	Cable LiYY
Interface connector	HE10 16P	Number of poles, min.	16-pole
Outer diameter	8 ± 1 mm	Connector PLC side	H0.14/10 (FERRULES 0.14mm ²)
Wire cross-section	0.14 mm ²		

Electrical Data

Total current, max.	3 A	Permissible current strength per path, max.	1 A
Rated voltage	≤ 60 V DC ≤ 25 V AC	Resistance	≤ 150 mΩ/m
Operating voltage	≤ 60 V DC ≤ 25 V AC	Capacity wire / wires	300 pF/m
Capacity wire / shield	300 pF/m		

Classifications

ETIM 6.0	EC000237	ETIM 7.0	EC000237
ETIM 8.0	EC000237	ETIM 9.0	EC000237
ETIM 10.0	EC000237	ECLASS 9.0	27-24-22-20
ECLASS 9.1	27-24-22-20	ECLASS 10.0	27-24-22-20
ECLASS 11.0	27-24-22-20	ECLASS 12.0	27-24-22-20
ECLASS 13.0	27-24-22-20	ECLASS 14.0	27-24-22-20
ECLASS 15.0	27-24-22-20		