
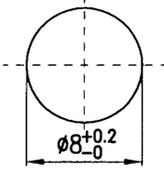
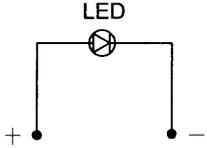


Rating	12V DC		
Insulation Resistance	DC 500V 100M ohm Min		
Dielectric Strength	AC 1000V 1 minite		
Operation Temperature	-40°C~+70°C		



LED Color	LED Lens Color	Vf	If	View Angle	mcd
Red	Red diffuse	12 V	8.5 mA	30°	30
Amber	Amber diffuse	12 V	8.5 mA	30°	15
Green	Green diffuse	12 V	8.5 mA	30°	20
Blue	Blue diffuse	12 V	7.5 mA	20°	750

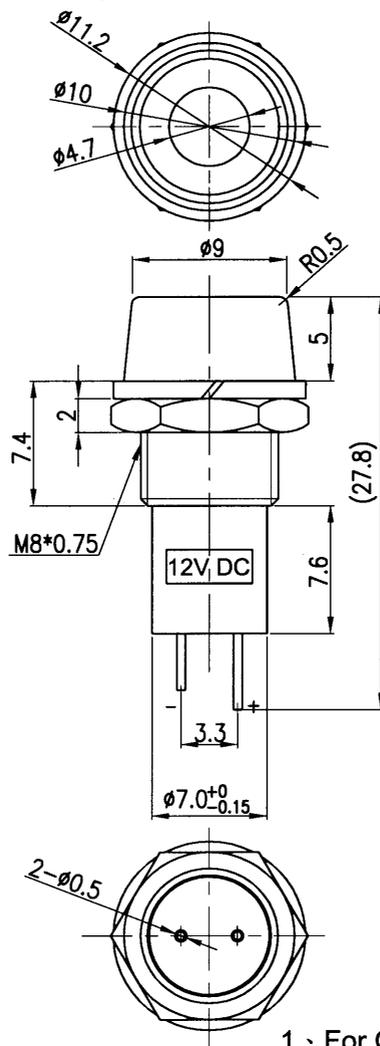


- 1 · For CEI Only
- 2 · Chromeplate
- 3 · Tolerances Unless Otherwise Specified ± 0.15

A4

							△
							△
Date	Name	Description				No.	
Drawn	Checked	Approved	SCI BOM No.	Model Name	LED HOLDER		
陳傑	楊建仁		Customer No.	Model No.	R9-126L(12V)	Rev.	
02/17/11	2/17-11	2/17-11	Unit	mm	Shin Chin Industrial Co., Ltd.		
						X0	

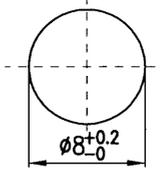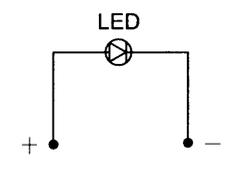Rating	24V DC		
Insulation Resistance	DC 500V 100M ohm Min		
Dielectric Strength	AC 1000V 1 minite		
Operation Temperature	-40°C~+70°C		

LED Color	LED Lens Color	Vf	If	View Angle	mcd
Red	Red diffuse	24 V	4.2 mA	30°	20
Amber	Amber diffuse	24 V	4.2 mA	30°	8
Green	Green diffuse	24 V	4.2 mA	30°	8
Blue	Blue diffuse	24 V	4mA	20°	300

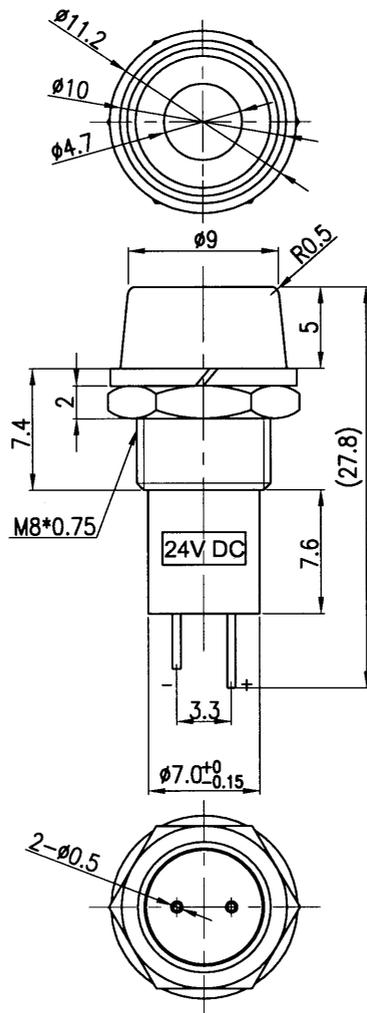

- 1 - For CEI Only
- 2 - Chromeplate
- 3 - Tolerances Unless Otherwise Specified ±0.15

A4

							△
							△
Date	Name	Description				No.	
Drawn	Checked	Approved	SCI BOM No.	Model Name	LED HOLDER		
陳傑	<i>楊建</i>	<i>7/7/11</i>	Customer No.	Model No.	R9-126L(24V)	Rev.	
02/17/11	2/17/11	2/17/11	Unit	mm	Shin Chin Industrial Co., Ltd.		
						X0	