 



Data Sheet

DSUB37M-39TB-3 D-SUB plug 90 ° Number of pins: 37

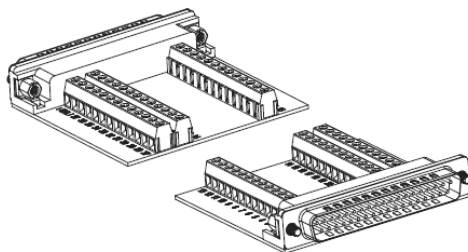


Terminal D-Sub

1	-----	1
2	-----	2
3	-----	3
.	-----	.
.	-----	.
.	-----	.
37	-----	37
SHL	-----	shell

Specification

Rating Voltage:	30VDC
Rating Current:	0.5A
Contact resistance:	30mΩ max.
Insulating resistance:	min. 100mΩ/500VDC
Operating temperature:	-10°C ~ +50°C

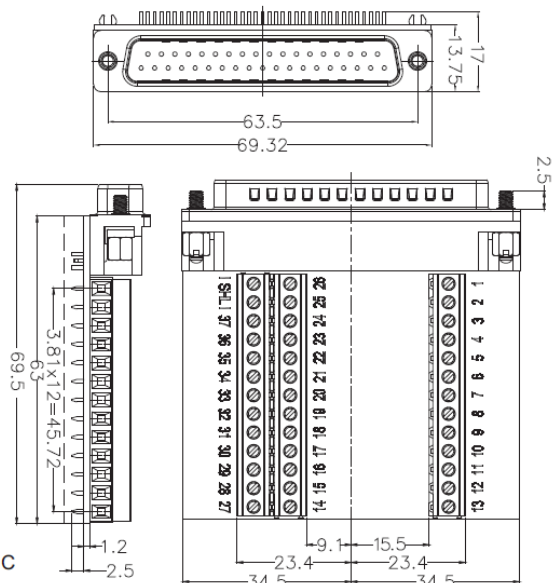

Data Sheet

Technical data

Connection	Screws
Type	DSUB 37 M-39 TB-3
Number of pins	37
Connector type	Plug, horizontal mount
No. of rows	2
Connection angle	90 °
Temperature range	-10–+50 °C