


Note

No.	A	B	C
09	16.33	24.99	30.81
15	24.66	33.32	39.14
25	38.38	47.04	53.04
37	54.83	63.50	69.32

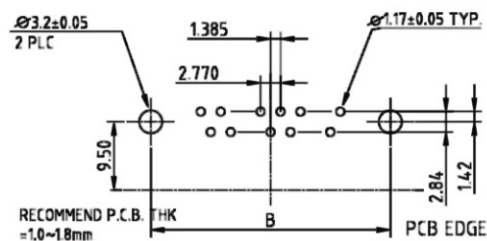

1. NO. OF CONTACTS:

09, 15, 25, 37

2. FLANGE MOUNTING OPTION:

WITH ASSEMBLED HEX SCREW BOLTS

ELECTRICAL CHARACTERISTICS

Contact Current Rating: 3Amperes.
 Dielectric Withstanding Voltage: AC 500V at sea level.
 Insulation Resistance: 1000Megohms Min.
 Contact Resistance: 30Milliohms Max.
 Operation Temperature : -55°C to +105°C.

Material

Contact : Copper Alloy.
 Insulator: PBT . (Select PA6T /LCP /PA9T)
 Shell: SPCC.
 Z-Piece: Fe.
 Screw: Copper Alloy.
 Rivet: Copper Alloy or Zinc.

