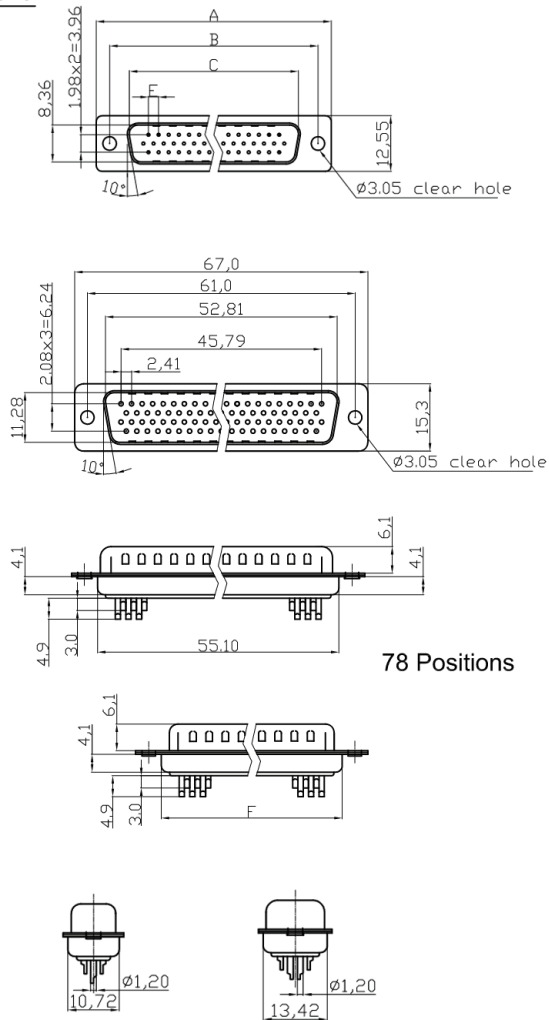
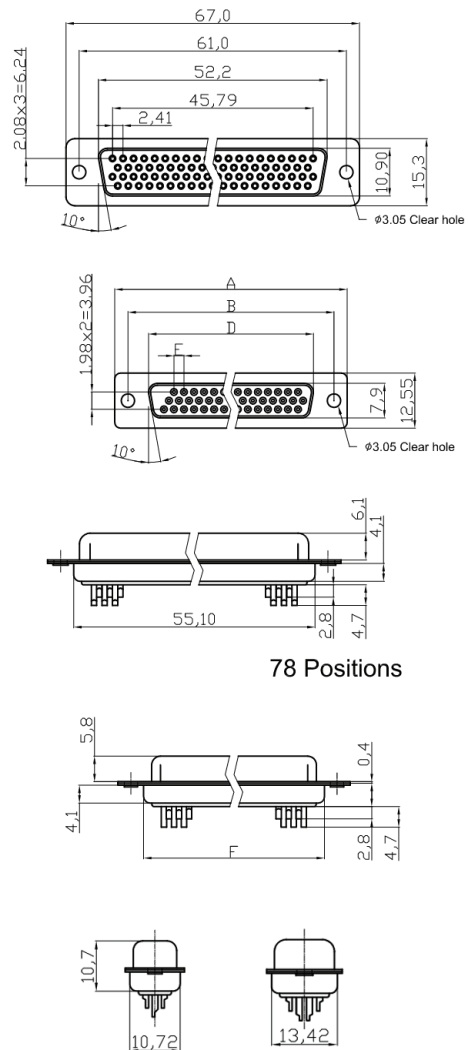


MaleFemale

Dimensions					
Positions	A	B	C	E	F
44	53.04	47.04	38.96	2.29	41.10

Dimensions					
Positions	A	B	D	E	F
44	53.05	47.04	38.40	2.29	41.10

Product Specification

Material

Insulator :Glass-Filled Thermoplastic PBT,UL94V-0 rated,Black
Contact : Copper alloy, Gold flash selective gold plating
Shell : Steel, 100u" Tin Over 50u" min Copper

Electrical

Contact Resistance :20 milliohms Max at 1 AMP DC.
Insulation Resistance :1000 megohms at 500 VDC
Dielectric Withstanding Voltage :1000 VAC/rms 60Hz for 1 minute
Current Rating : 3 AMP
Voltage Rating :250 VAC/rms 60Hz
Operating Temperature: -20°C ~ +85°C

NOTES:

MATERIAL

Insulator Material:Glass-filled thermoplastic PBT,UL94V-0 rated,Black
Contact Material:Copper alloy, Gold flash selective gold plating
Shell :Steel, 100 μ" Tin Over 50μ" min Copper

Electrical

Contact Resistance :20 milliohms Max at 1 AMP DC.
Insulation Resistance :1000megohms at 500 VDC
Dielectric Withstanding Voltage:1000 VAC/rms 60Hz for 1 minute
Current Rating :3 AMP
Voltage Rating :250 VAC/rms 60Hz
Operating Temperature : -20°C+85°C

RoHS compliant
Unit: mm



File No.: E198287