 
 
 
 
 
 
 
 

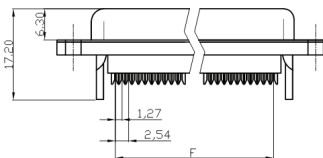
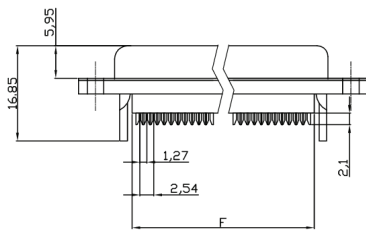
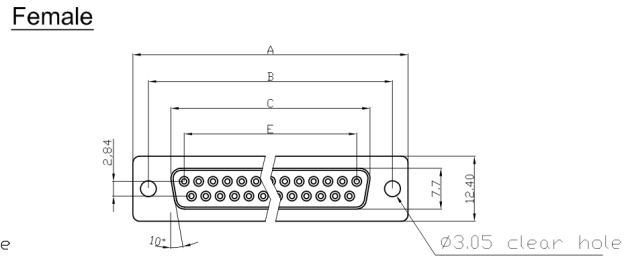


Datasheet

Item no. 1586485

V1_0617_02_EN

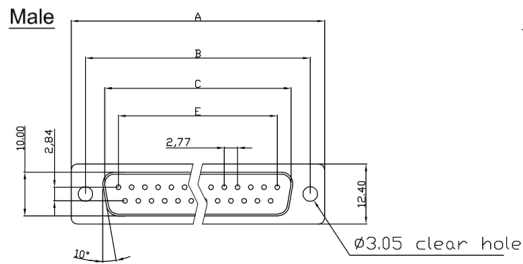

Dimensions					
Positions	A	B	C	E	F
9	30.50	25.00	18.05	11.08	13.10

Dimensions					
Positions	A	B	C	E	F
9	④ 30.50	24.99	④ 16.00	11.08	10.16

Product Specification

Material

Insulator : Glass-Filled Thermoplastic PBT, UL94V-0
Contact : Copper alloy

Electrical

Contact Resistance : 20 milliohms Max at 1 AMP DC.
Insulation Resistance : 1000 magohms at 500 VDC
Dielectric Withstanding Voltage : 1000 VAC/rms 60Hz for 1 minute
Current Rating : 3 AMP
Voltage Rating : 250 VAC/rms 60Hz
② Wire Spec : 26 AWG-28 AWG
Operating Temperature: -55°C ~ +105°C

Product Specification

Material

Insulator : Glass-Filled Thermoplastic PBT, UL94V-0,Black
Contact : Copper alloy, Gold flash selective gold

Electrical

Contact Resistance : 20 milliohmsMax at 1 AMP DC.
Insulation Resistance : 1000 magohms at 500 VDC
Dielectric Withstanding Voltage : 1000 VAC/rms 60Hz for 1 minute
Current Rating : 3 AMP
Volatge Rating : 250 VAC/rms 60Hz
② Wire Spec : 26 AWG-28 AWG
Operating Temperature: -55°C+105°C



File No.: E198287

RoHS compliant

Unit: mm