

Data Sheet


TECHNICAL SPECIFICATIONS

D-Sub Hood:


- Material: UL Recognised Plastic Material
- Plating: Nickel over Copper
- Operating Temperature: -55°C to +110°C
- Cable Entry: Top Entry
- Thumbscrews: UNC 4-40 (Standard)
- Cable O.D: Up to 13mm

Female D-Sub Solder Cup:

- Insulator: PBT, Black, UL94 V-0
- Shell: Steel, Tin Plated
- Contact pins: Copper Alloy
- Stamped & Formed Pins: Class 3, 100 inserts min.
- Machined Contact Pins: Class 1, 500 inserts min.
- Contact Plating: Selective Gold over Nickel
- Operating Temperature: -55°C to +105°C
- Withstanding voltage: 1000V for 1 minute
- Insulator resistance: 1000MΩ min
- Insulator resistance: 1000MΩ min

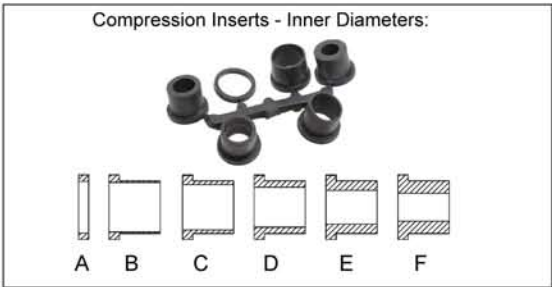

| Size | A     | B     | C    | D    | E    | F |
|------|-------|-------|------|------|------|---|
| 9/15 | 8,10  | 8,00  | 7,25 | 6,50 | 5,30 | - |
| 25   | 11,40 | 10,40 | 9,40 | 7,60 | 5,80 | - |

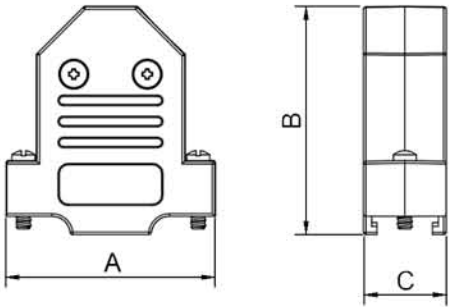

| Size DTNT | Dim A | Dim B | Dim C |
|-----------|-------|-------|-------|
| 9-way     | 31,5  | 43,5  | 15,8  |
| 15-way    | 39,9  | 43,5  | 15,8  |
| 25-way    | 54,0  | 47,5  | 15,8  |