

## Data Sheet


### TECHNICAL SPECIFICATIONS

#### D-Sub Hood:


|                        |                                |
|------------------------|--------------------------------|
| Material:              | UL Recognised Plastic Material |
| Plating:               | Nickel over Copper             |
| Operating Temperature: | -55°C to +110°C                |
| Cable Entry:           | Side Entry                     |
| Thumbscrews:           | UNC 4-40 (Standard)            |
| Cable O.D:             | Up to 13mm                     |

#### D-Sub High Density:

|                        |                            |
|------------------------|----------------------------|
| Insulator:             | PBT, Black, UL94 V-0       |
| Shell:                 | Stamped Steel, Tin Plated  |
| Contact pins:          | Copper Alloy               |
| Stamped & Formed pins: | 100 inserts min            |
| Contacts Plating:      | Selective Gold over Nickel |
| Operating Temperature: | -55°C to +105°C            |
| Withstanding voltage:  | 500V for 1 minute          |
| Insulator resistance:  | 500MΩ min                  |

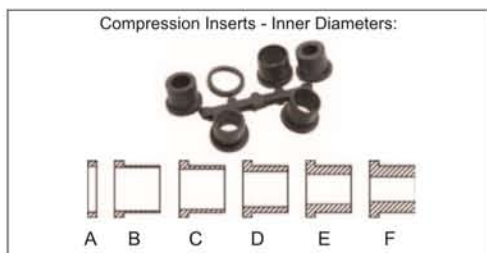

| Size | A     | B     | C    | D    | E    | F |
|------|-------|-------|------|------|------|---|
| 9/15 | 8,10  | 8,00  | 7,25 | 6,50 | 5,30 | - |
| 25   | 11,40 | 10,40 | 9,40 | 7,60 | 5,80 | - |

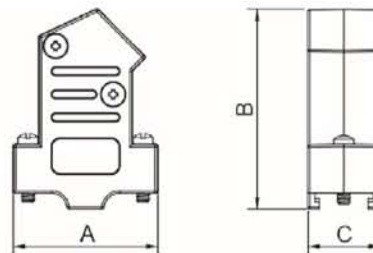

| Size D45NT | Dim A | Dim B | Dim C |
|------------|-------|-------|-------|
| 9-way      | 31,5  | 43,5  | 15,8  |
| 15-way     | 39,9  | 43,5  | 15,8  |
| 25-way     | 54,0  | 47,5  | 15,8  |