

Data Sheet


TECHNICAL SPECIFICATIONS

D-Sub Hood:


- Material: UL Recognised Plastic Material
- Plating: Nickel over Copper
- Operating Temperature: -55°C to +110°C
- Cable Entry: Top Entry
- Thumbscrews: UNC 4-40 (Standard)
- Cable O.D: Up to 13mm

Male D-Sub Solder Cup:

- Insulator: PBT, Black, UL94 V-0
- Shell: Steel, Tin Plated
- Contact pins: Copper Alloy
- Stamped & Formed Pins: Class 3, 100 inserts min.
- Machined Contact Pins: Class 1, 500 inserts min.
- Contact Plating: Selective Gold over Nickel
- Operating Temperature: -55°C to +105°C
- Withstanding voltage: 1000V for 1 minute
- Insulator resistance: 1000MΩ min
- Insulator resistance: 1000MΩ min

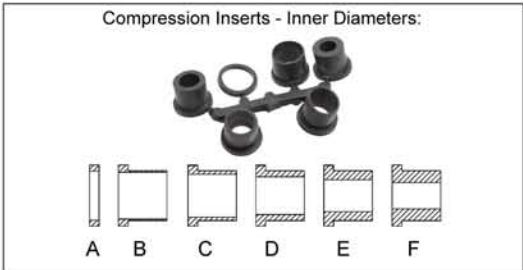

Size	A	B	C	D	E	F
9/15	8,10	8,00	7,25	6,50	5,30	-
25	11,40	10,40	9,40	7,60	5,80	-

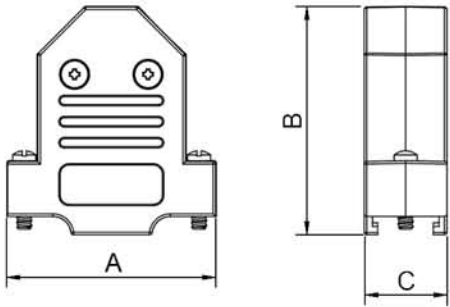

Size DTNT	Dim A	Dim B	Dim C
9-way	31,5	43,5	15,8
15-way	39,9	43,5	15,8
25-way	54,0	47,5	15,8