
 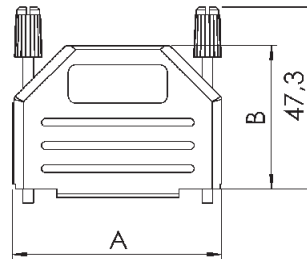



# D-Sub Backshells OS-DPPK Series

## TECHNICAL SPECIFICATIONS

Material:	Nylon UL94 V-2
Temp. range:	-55°C - 105°C
Cable strain relief:	Cable clamp with self-tapping screws
Cable diameter:	3.0 - 11.0 mm
Locking screws:	Long jackscrews with moulded top for colour coding
Cable outlet:	Top

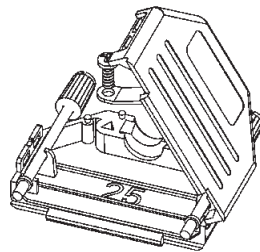

TYPE	A	B
DPPK9	32,4	31,3
DPPK15	40,7	30,8
DPPK25	54,4	37,3
DPPK37	70,9	36

## PART NUMBERING SYSTEM

15-1147	9-way black	15-1163	9-way yellow
15-1148	15-way black	15-1164	15-way yellow
15-1149	25-way black	15-1165	25-way yellow
15-1150	37-way black	15-1166	37-way yellow
15-1151	9-way blue	15-1167	9-way light grey
15-1152	15-way blue	15-1168	15-way light grey
15-1153	25-way blue	15-1169	25-way light grey
15-1154	37-way blue	15-1170	37-way light grey
15-1155	9-way red	15-1171	9-way white
15-1156	15-way red	15-1172	15-way white
15-1157	25-way red	15-1173	25-way white
15-1158	37-way red	15-1174	37-way white
15-1159	9-way green		
15-1160	15-way green		
15-1161	25-way green		
15-1162	37-way green		

## FEATURES

- Available in sizes 9, 15, 25 and 37
- Hinged single piece moulding with retaining latches
- Light weight and cost effective
- Compact and attractive design
- Suitable for high-integrity data links
- No special assembly tools required