


BNC Female Terminal connector

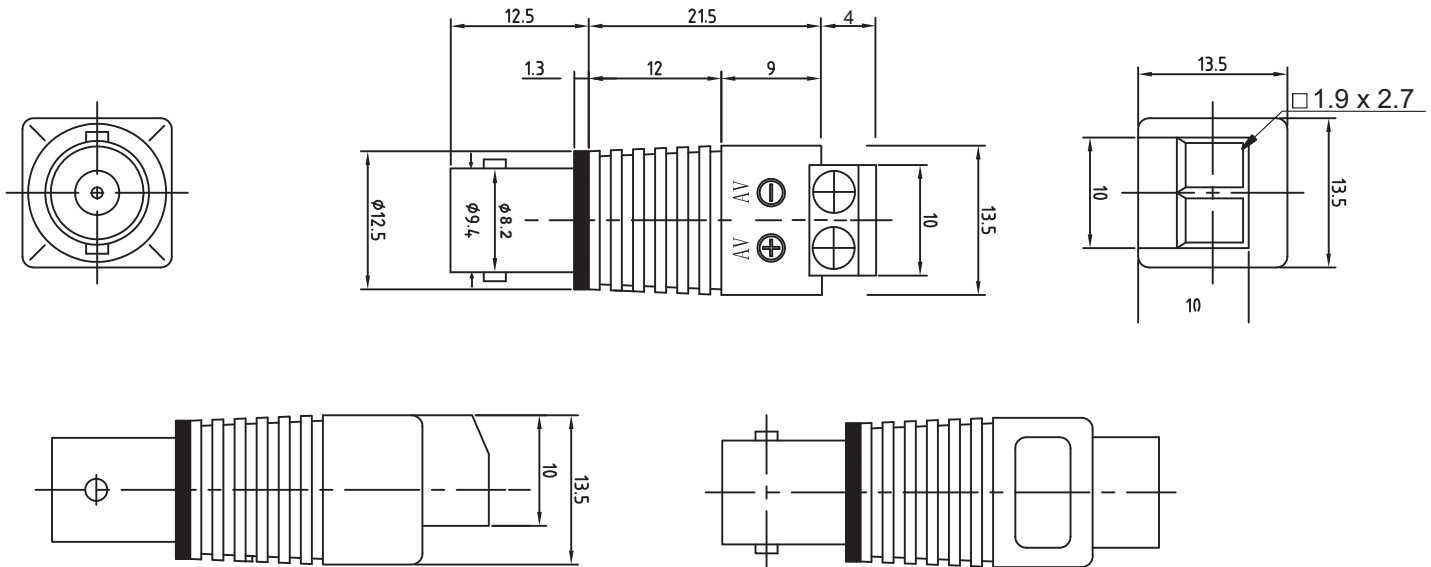

Technical Data:

Electrical:

Frequency Range: DC-1GHz
 Normal Impedance: 50Ω
 Voltage rating: 12VDC
 Current rating: 5A
 Contact Resistance: Center 1.5mΩ and outer 0.2mΩ
 Dielectric withstanding voltage: 1500V
 Wire range: 26-14AWG

Mechanical:

Torque: 0.4Nm (3.5lb/in)
 Operating temperature: -40°C to 105°C