

Product: 1m USB 3.1 Type C (M) to Type A (M) Cable

Order Code: 16-1737


Features

- Type A to Type C
- Male to male connectors
- Data Transfer Rate: 10Gbps
- Charging Output: 3A
- Length: 1m
- Black



Applications

This cable meets USB3.1 specification and has USB type C connectors. It is capable of DisplayPort Alt mode bandwidth allowing 4k resolutions. With power delivery 2 (PD2) it is also able to carry 20v / 3° (60watts) of power.

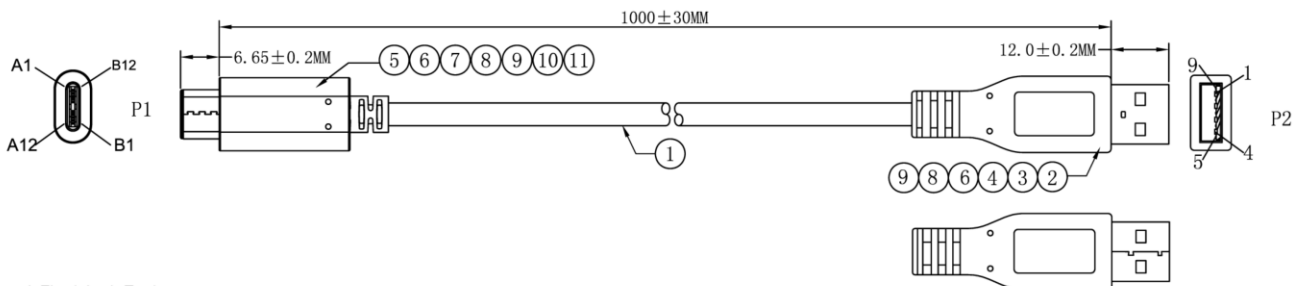

1. Electrical Test:

1. 100% Test(Open ,short ,miss wire)
2. Contact Resistance: 2 ohm max.
3. Insulation Resistance: 10M ohm min.
4. Hi-pot: 300V DC/10ms

| | | | |
|---|--|------|-----|
| 9 | USB TYPE C~UP Tinplate Nickel Plated~ | 1 | pcs |
| 8 | USB TYPE C~Below Tinplate Nickel Plated~ | 1 | pcs |
| 7 | Inside Molding:Low pressure material | 2 | g |
| 6 | USB 3.1 C Type Connector Nickel Plated Shell With PCBA(Resistance:56KΩ) | 1 | pcs |
| 5 | Outside Molding 45P PVC Color:Black | 16 | g |
| 4 | USB 3.0 A(M) Rear Shell Nickel plated | 1 | pcs |
| 3 | USB 3.0 A(M) Front Shell Nickel plated | 1 | pcs |
| 2 | USB 3.0 A(M) 9P /Insulation:BULE,PIN. Gold Plated 3U" | 1 | pcs |
| 1 | USB3.1-[30AWG+EAM]*2P+[30AWG+A]*1P+24AWG*1C+A2EB(16/8/0.10TC 85%TC)OD:4.5MM-BIack-NO-MARKING | 1.02 | M |

