
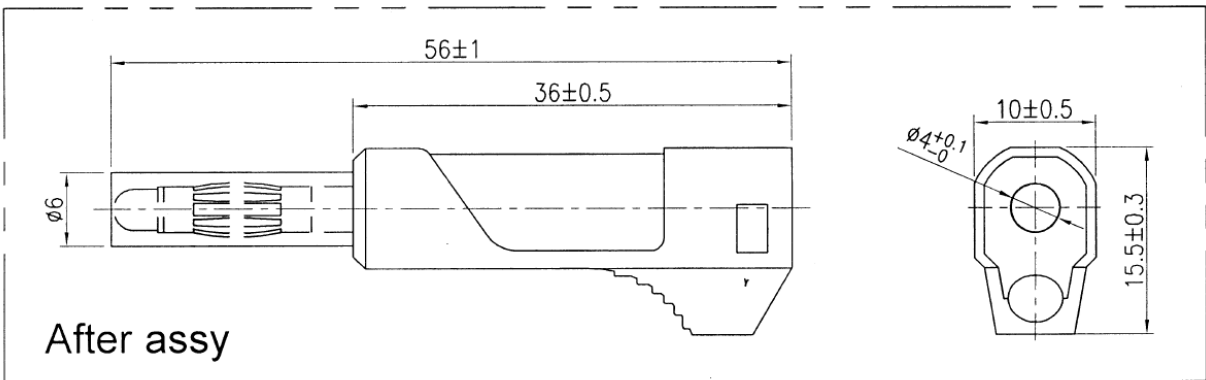


Data Sheet

B miniature male connector, straight pin-Ø: 4 mm black 1 pc.

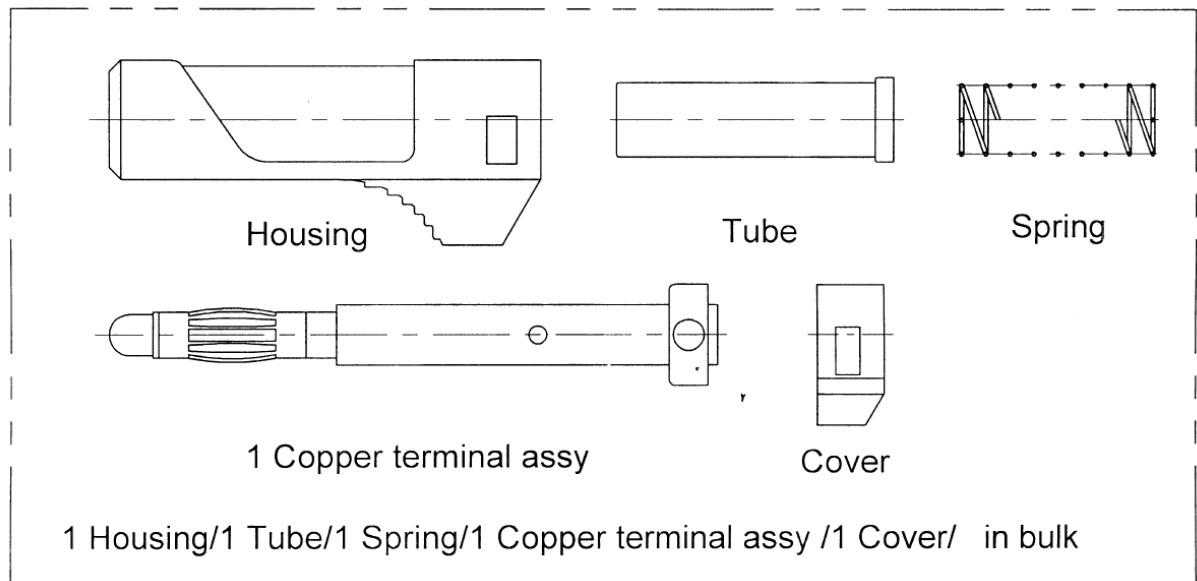

*in bulk

Tolerances ± 0.3 Unless Otherwise Specified

Rating	30A
Insulation Resistance	DC 500V 100M Ω Min.
Dielectric Strength	AC 1500V 1 minute.
Operation Temperature	-20°C~+80°C
Color	Black

Material:

Plug: nickel plated heat treated beryllium copper.

Handle: nylon.

Fits $\varnothing 4$ mm banana plug or O.D. less than $\varnothing 4$ mm wire by soldering.

Sliding sleeve for plug.

Fits $\varnothing 4$ mm standard banana socket.