

## 4mm connectors

Order code	Manufacturer code	Description
17-2346	1066IEC RG	STACK.SHROUDED 4MM PLUG RED (RC)
17-2348	1066IEC JA	STACK.SHROUDED 4MM PLUG YELLOW (RC)
17-2340	1066IEC NR	STACK.SHROUDED 4MM PLUG BLACK (RC)
17-2342	1066IEC BL	STACK.SHROUDED 4MM PLUG BLUE (RC)
17-2344	1066IEC VERT	STACK.SHROUDED 4MM PLUG GREEN (RC)


4mm connectors	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

## 4mm Shrouded In-line Stackable Plugs

### Electro PJP – Standardised IEC 1010 Version

A range of professional quality fixed sleeve stackable shrouded 4mm plugs with brass centre pins and lantern style spring contacts which comply with the safety requirements of **IEC1010 Category 3**. Screw connection which is tightened using a 1.5mm hex key.


#### Photograph

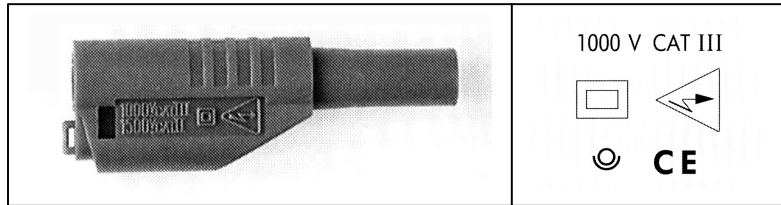

#### Specification

Connector insulation material	:	Polyamide
Connector contact material	:	Brass and bronze Ni
Voltage	:	1,000 V
Maximum current	:	36 A
Temperature range	:	-20°C to +80°C

#### Technical Drawing

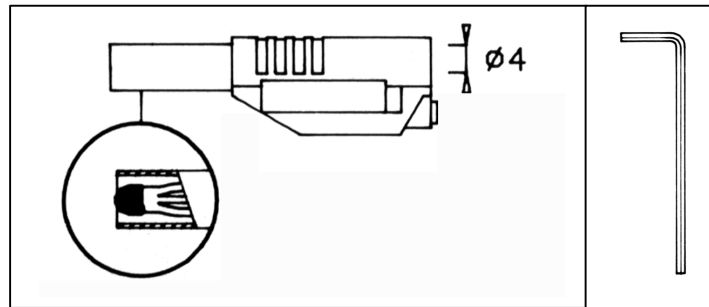

PJP Ref No.	Description	Colour
1066 IEC N	4mm Stackable Fixed Sleeve Stackable Safety Plug	Black
1066 IEC Bl	4mm Stackable Fixed Sleeve Stackable Safety Plug	Blue
1066 IEC V	4mm Stackable Fixed Sleeve Stackable Safety Plug	Green
1066 IEC R	4mm Stackable Fixed Sleeve Stackable Safety Plug	Red
1066 IEC J	4mm Stackable Fixed Sleeve Stackable Safety Plug	Yellow
3315	1.5mm Hex Key Spanner	-