



1x 'AAA' Cell Holder with Solder Tags

Order code: **18-0572**



Specification:

Plastic material: polypropylene

Flammability rating: UL94 HB, UL File No. E216959

Temperature range: -10°C to +100°C

Springs: nickel plated spring steel

Rivets: brass, nickel plated

Contact resistance: under 50mΩ for +/- contacts per EIA-540J000




RoHS 2 compliant

Mounting instructions:

Use 2-56 machine screws or eyelets 0.089in OD by 0.15in flange
Stimpson GS-3 series or equivalent.

Adhesive and double sided tapes also work well.

Tolerances	mm (inches)
Decimal	±0.5 (0.020)
Fractional	±0.8 (0.030)
Angular	±3°

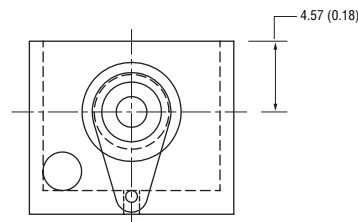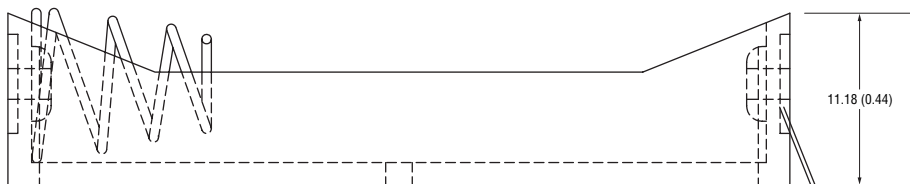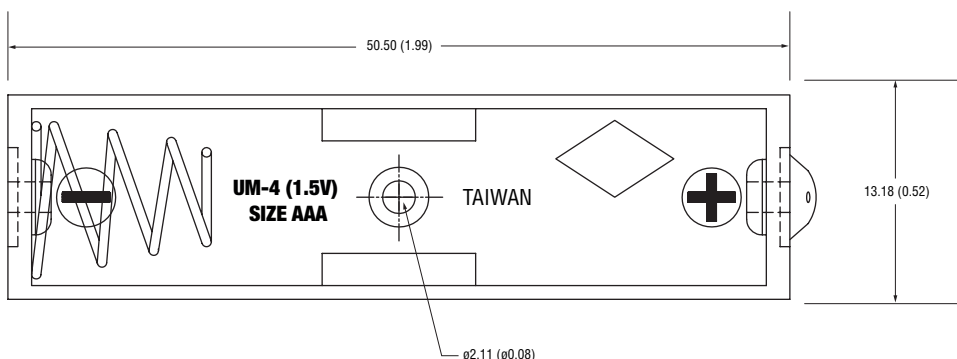

www.rapidonline.com