

2x 'AAA' Cell Holder with Flying Leads

Order code: **18-0574**

Specification:

Housing: black polypropylene

Flammability rating: UL94 HB, UL File No. E216959

Temperature range: -10°C to $+100^{\circ}\text{C}$



Springs: nickel plated spring steel

Rivets: brass, nickel plated

Wire: 26 AWG, UL1007, CSA, TR64

Contact resistance: under $50\text{m}\Omega$ for +/- contacts per EIA-540J000

RoHS 2 compliant

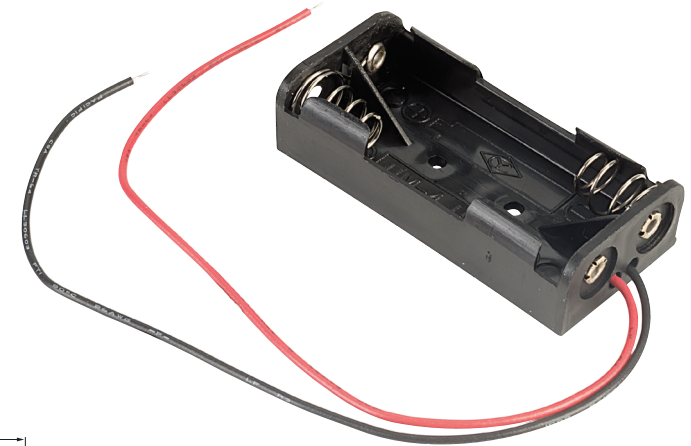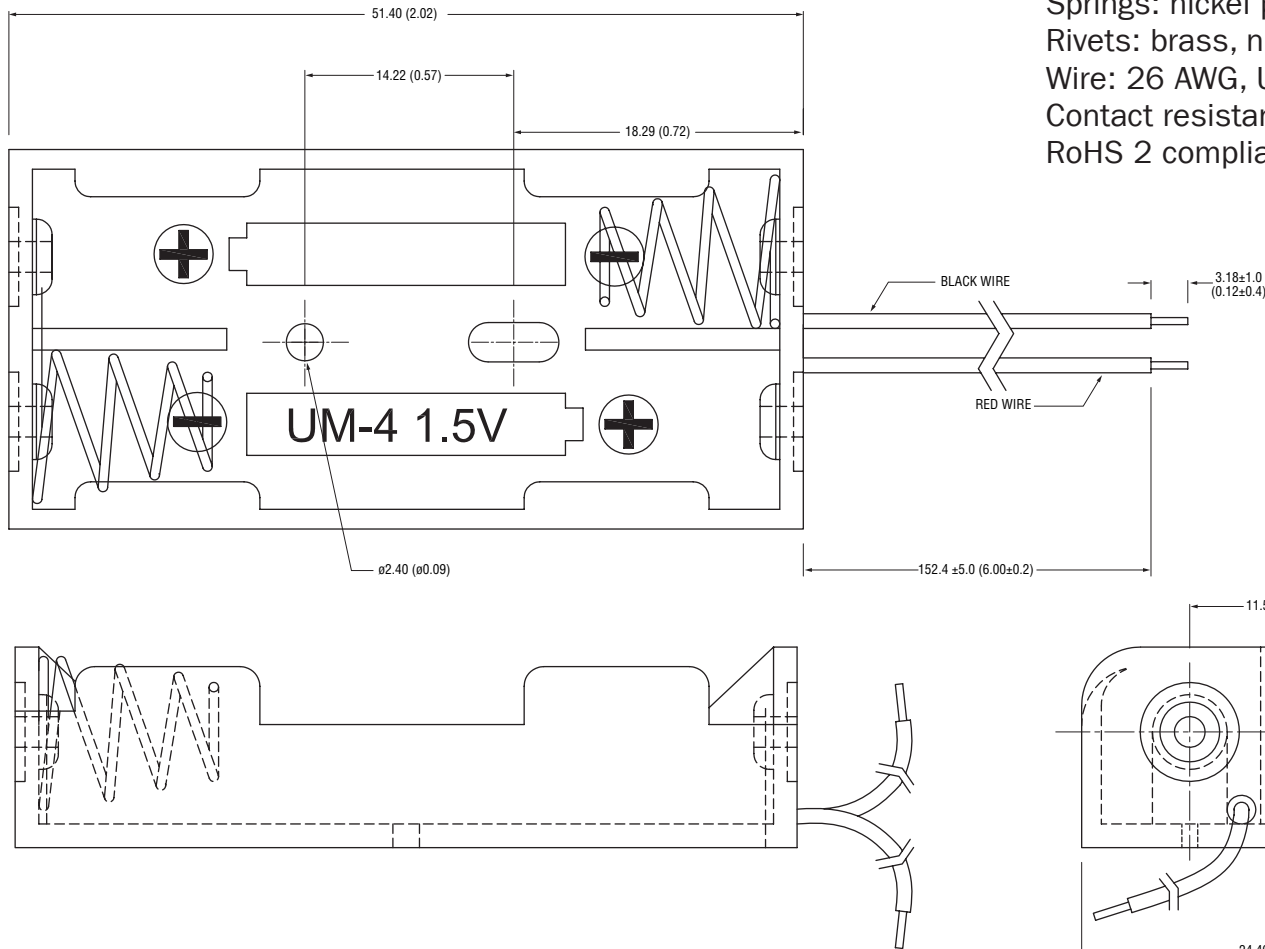

Tolerances	mm (inches)
Decimal	± 0.5 (0.020)
Fractional	± 0.8 (0.030)
Angular	$\pm 3^{\circ}$