

Specification:

Housing: black polypropylene

Flammability rating: UL94 HB, UL File No. E216959

Temperature range: -10°C to +100°C

Rivets: brass, nickel plated

Springs: spring steel, nickel plated

Contacts: spring steel, nickel plated

Contact resistance: under 50mΩ for +/- contacts
per EIA-540J000


RoHS 2 compliant

Mounting instructions:

Use 2-56 machine screws or eyelets 0.089in OD by 0.15in flange

Stimpson GS-3 series or equivalent.

Adhesive and double sided tapes also work well.

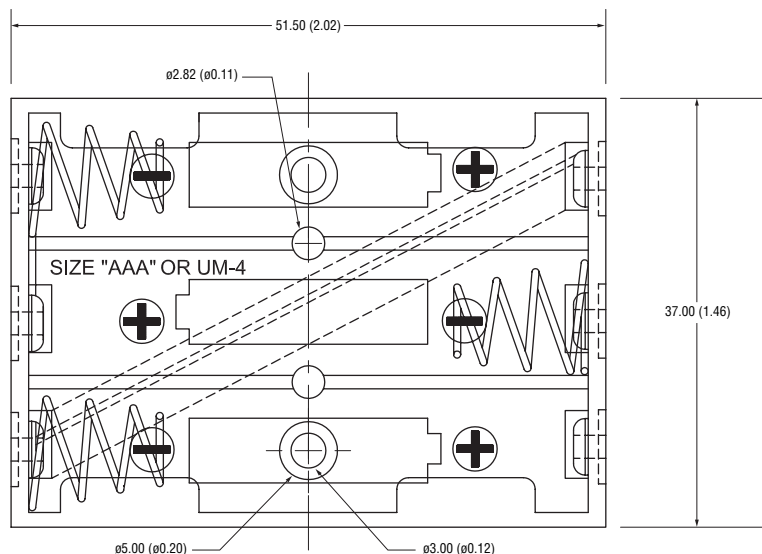

Tolerances	mm (inches)
Decimal	±0.5 (0.020)
Fractional	±0.8 (0.030)
Angular	±3°

