

Specification:

Housing: black polypropylene

Flammability rating: UL94-HB, UL File No. E216959


Temperature range: -10°C to $+100^{\circ}\text{C}$

Rivets: brass, nickel plated

Wires: 26 AWG, UL1007, CSA-TR-64, 300V, 80°C

Spring: spring steel, nickel plated

Contact resistance: under $50\text{m}\Omega$ for +/- contacts per EIA-540J000

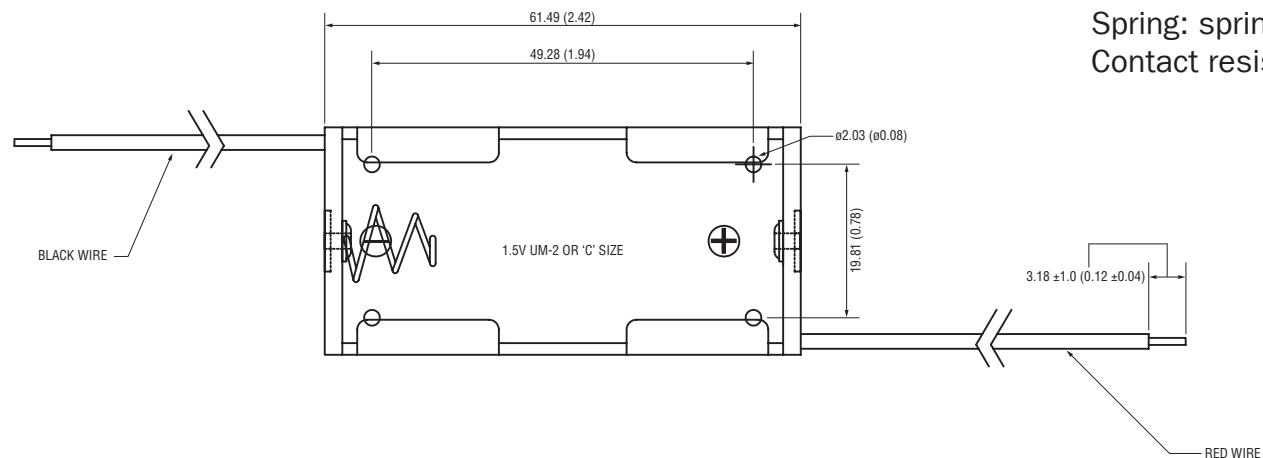

Tolerances	mm (inches)
Decimal	± 0.5 (0.020)
Fractional	± 0.8 (0.030)
Angular	$\pm 3^{\circ}$

