

## Specification

**Model Name : AC 0224A**




**IDEAL POWER**  
IDEAL POWER SOLUTIONS

Input Voltage	100 ~ 240 Vac
Input Frequency	47 ~ 63Hz
Max. In-rush Current	Cold start , 15A for 115Vac , 30A for 230Vac
Input Current	1.6A Max for 115Vac 0.8A Max for 230Vac
Output Voltage	29.2Vdc 27.4Vdc
Max. Charging Current	2A
Working Temperature	0 ~ 50 Degree C
Hold up time	8 ms at full load output power and 115Vac input
LED Indication	LED1 : RED LED → CHARGING LED2 : GREEN LED → FULL CHARGE
Dimensions	4.72 inch ( 120 mm ) Length 2.48 inch ( 63 mm ) Width 1.30 inch ( 33 mm ) Height



**IDEAL POWER**  
IDEAL POWER SOLUTIONS

### Charging Curve :

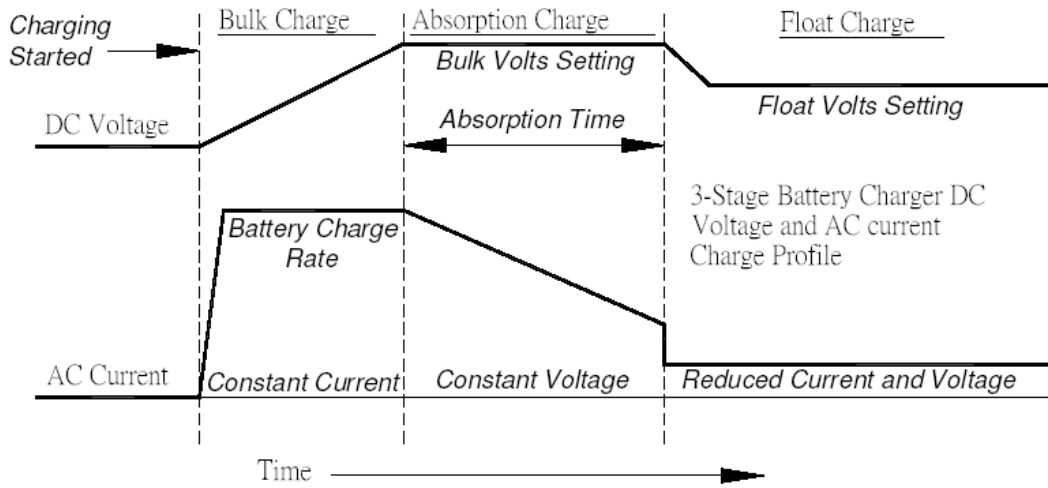

### Case Drawing

Body View





**IDEAL POWER**  
IDEAL POWER SOLUTIONS

Front Panel



Rear Panel

