


MAX PLUS EP522

9V



Industry Standard Dimensions

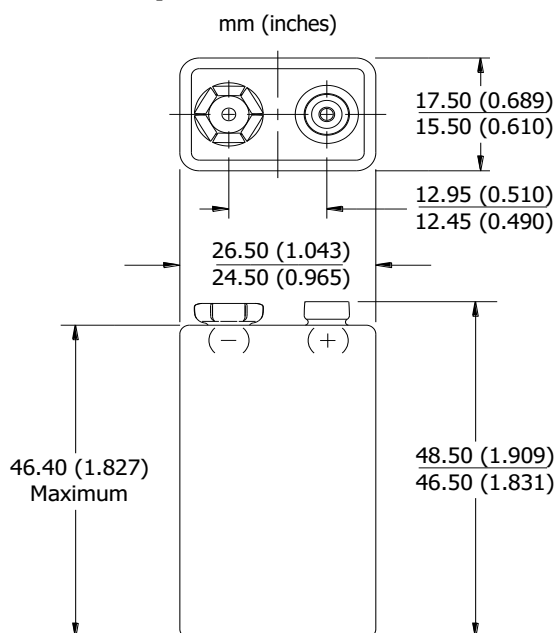


Specifications


Classification:	Alkaline
Chemical System:	Zinc-Manganese Dioxide (Zn/MnO ₂)
	No added mercury or cadmium
Designation:	ANSI 1604A, IEC-6LF22 or 6LR61
Nominal Voltage:	9.0 volts
Operating Temp:	-18°C to 55°C
Typical Weight:	45 grams
Typical Volume:	21 cubic centimeters
Shelf Life:	5 years at 21°C
Terminal:	Miniature Snap

Continuous Discharge


to 4.8 volts at 21°C

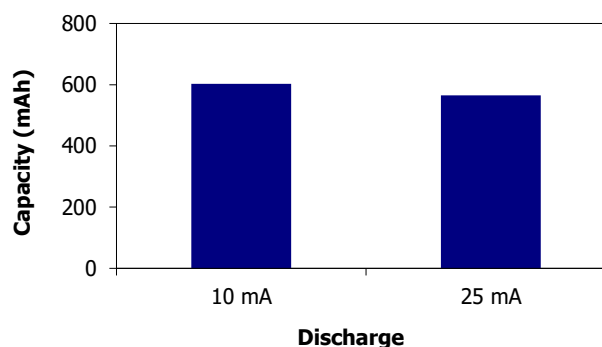

INDUSTRY STANDARD TOY TEST 270 ohm 1 hr/day

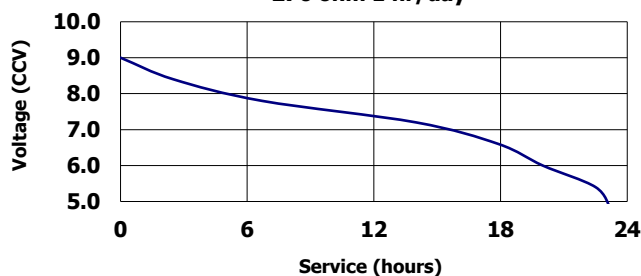

Battery Selection Indicator

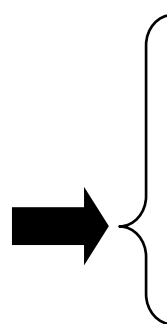

High Drain Devices

Toy
Baby Monitor

Moderate Drain Devices

Garage Opener

Low Drain Devices

Clock Radio
Smoke Alarm

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.