

634041

European Region

BRIGHT

- Five LEDs provide 35 lumens



HANDY

- Easy to operate pushbutton tailcap switch



METAL

- Aluminum casing



ECONOMICAL

- LEDs never need replacing
- One and a half hours of use between battery changes (with Eveready SHD AA cells)



Lightweight and compact, the Energizer® Value Metal torch is an economical general lighting choice. It has an aluminum body and an easy to operate pushbutton tailcap switch. Providing 35 lumens of light, this flashlight will allow you to make out objects up to 34 meters away, making it handy for household use. In addition, the small size and slim design makes it easy to carry in pocket, purse, toolbox or backpack




Before Using Your Flashlight:
Please read all instructions and cautionary markings on the package and light

European Region Product Detail:

- Designation:** Energizer Value Metal
SAP: 634041
Colour: Gunmetal Grey
Power Source: Two "AA"
IEC: LR6
Lamp: Five White LEDs
Lamp Life (hr): Lifetime
Lamp Output (lumens): 35
Beam Distance (m): 34
Peak Beam Intensity (cd): 355
Run Time (h:mm): 3 hr with Energizer MAX batteries
Typical Weight: 34 grams without batteries
Dimensions (mm): 23 x 143

Performance:

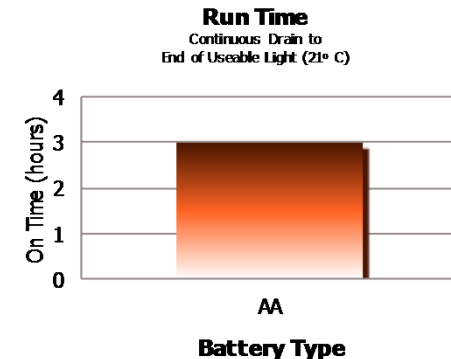

Tested according to ANSI/NEMA FL 1 Standards.

Important Notice

This datasheet contains information specific to products manufactured at the time of its publication
Contents herein do not constitute a warranty
 ©Energizer / All Rights Reserved