


ENERGIZER 13 size - **Mercury Free**

ZnAir



Industry Standard Dimensions

mm (inches)

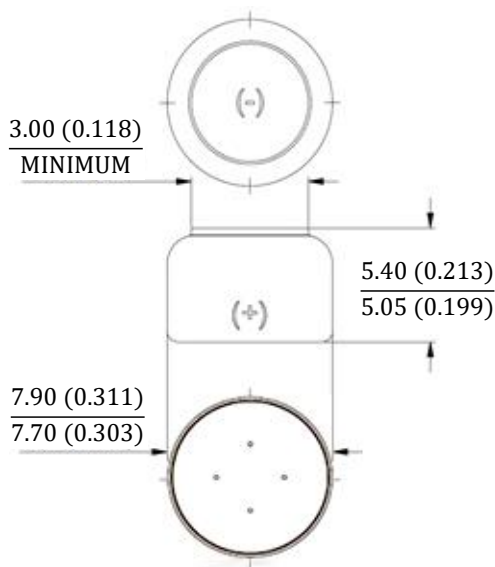


General Information

Chemical System:	Zinc Air (Zn/O ₂)
Tab Color:	Orange
Designation:	ANSI-7000ZD, IEC-PR48
Nominal Voltage:	1.4 Volts
Typical Capacity:	273 mAh (to 1.05 volts) (IEC-STD at 12/3 mA at 21°C)
Typical Weight:	0.8 grams (0.03 oz.)
Typical Volume:	0.3 cubic centimeters (0.02 cubic inch)


Typical Discharge Characteristics

ANSI/IEC Industry Standards / Standard Test Protocol
(12/3 mA .1S/1H59M 59.9S 12H at 21°C)

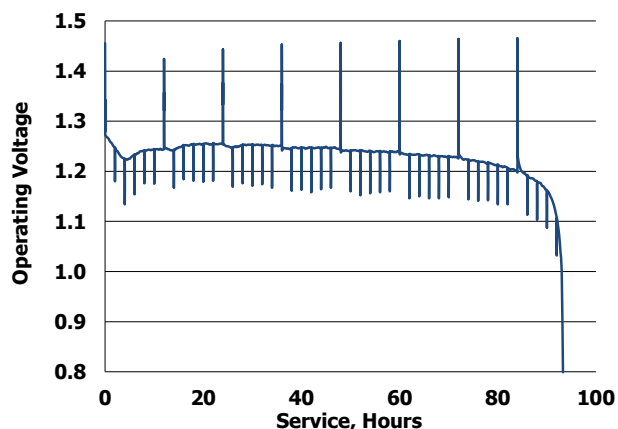

Typical Discharge Characteristics

ANSI/IEC Industry Standards / Wireless Streaming Protocol
(5mA 15 min/ 3mA 45 min 12H cycle at 21°C)

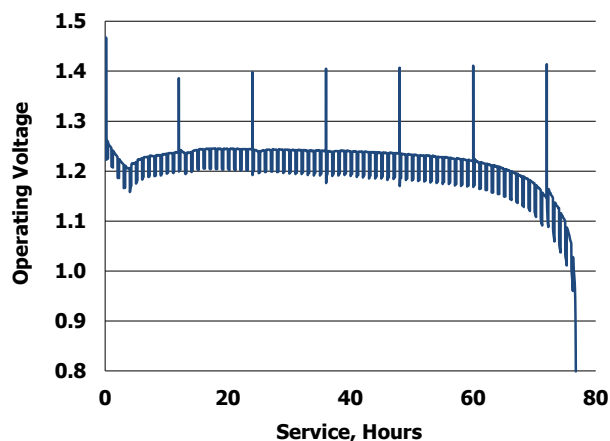

Important Notice

This datasheet contains typical information specific to products manufactured at the time of its publication.
Contents herein do not constitute a warranty and are for reference only.