


DURACELL®






DC1604

170mAh 9V

Duracell Rechargeable

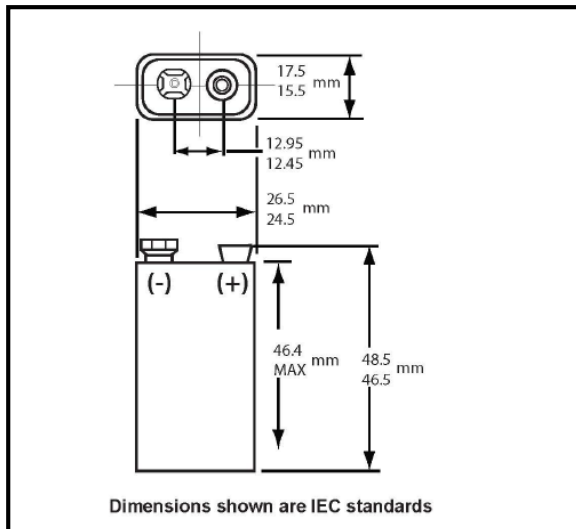

Specifications	
Classification:	Prismatic Rechargeable
Chemical System:	Nickel Metal Hydride (NiMH)
Designation:	IEC – 6HR61
Nominal Voltage:	8.4V
Operating Voltage:	7.0V – 9.5V
Operating Temperature:	-10°C to 50°C
Storage Temperature:	5°C to 30°C
Typical Weight:	49.3g
Typical Volume:	22.8 cm ³
Typical Impedance:	900 mΩ @1kHz
Rated Capacity:	170mAh
Safety Features:	Short Circuit Protection

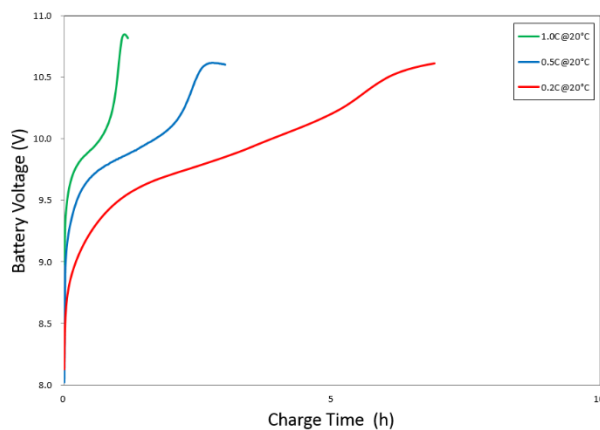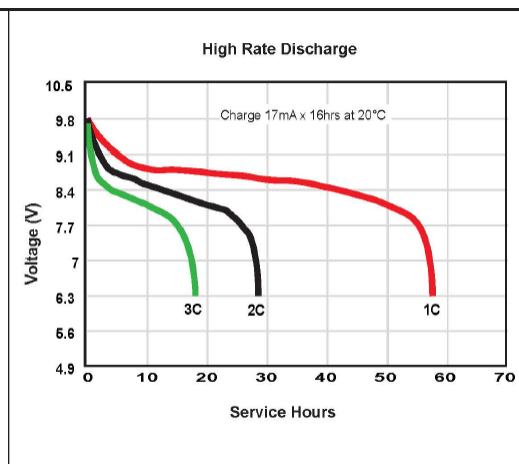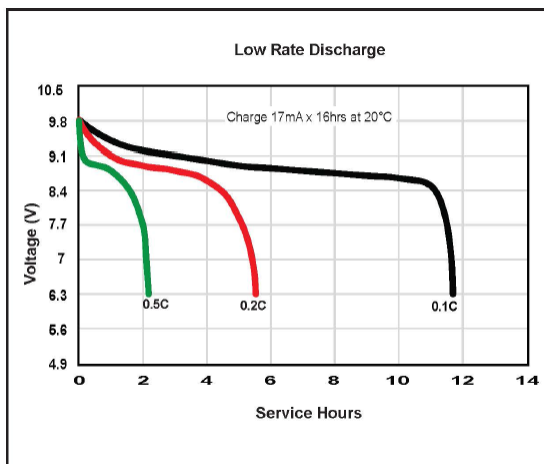

Information and contents in this data sheet are for reference purposes only. They do not constitute any warranty and representation is subject to change without notice. For most current information and further details, please contact Duracell.