

377 **0%**
MERCURY

SR626SW (SR66)
Watch Battery
Swiss Made

Technical Data Sheet


Specifications

Chemical system	Zinc / Monovalent Silver Oxide, low drain
Nominal Voltage	1,55 V
Capacity	24 mAh, Discharge over 34,8 kΩ at 20°C to 1,2 V
Operating Temperature	0°C – 60°C
Self Discharge	Less than 5% per year at 20°C
Weight	~0,40 g

Dimensions


(according to IEC 60086-3)

Diameter	6,80 mm (0,268")
Height	2,60 mm (0,102")

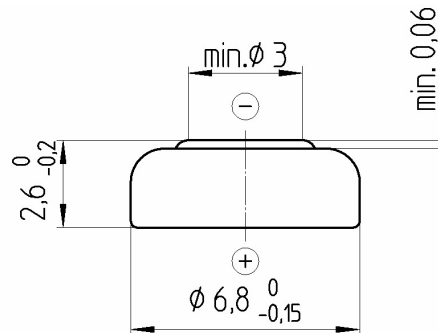

Discharge Curve

Constant Load	34,8 kΩ
Starting Drain	44,8 μA
Temperature	20°C

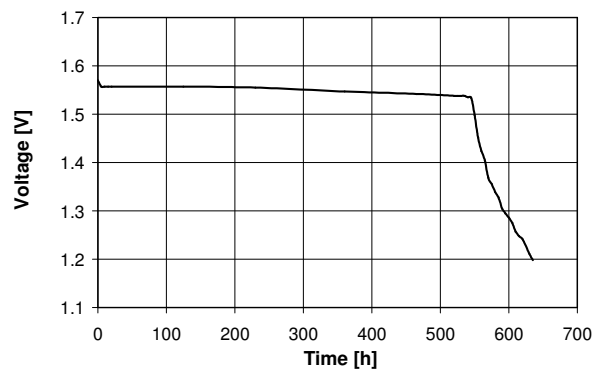

Information and contents in this data sheet are for reference purpose only. They do not constitute any warranty or representation and are subject to change without notice. For most current information and further details, please contact your Renata representative. For safety related information please consult the PSDS document related to that product or product family.

Rev. 377MF.03 2010/11