 
 
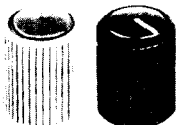
 
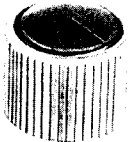
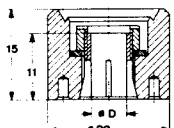
 
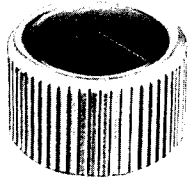
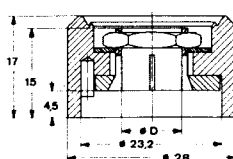
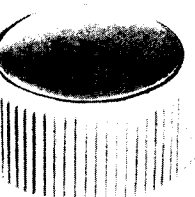
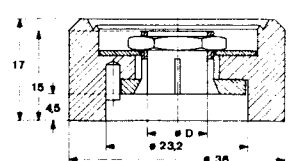
 
 
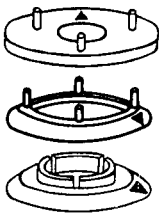
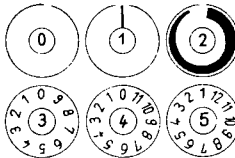
 
 
 
 
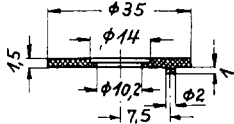
 
 
 
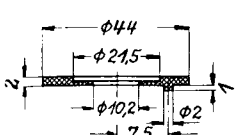
 
 


Meßgeräte-Knöpfe
mit Spannzangenbefestigung
- dekorativ farbloso eloxiert, schwarz

Instrument Knobs collet fixing
Bouton en Aluminium
- dekorativ anodized, non colored, black

					Knöpfe Knobs		Zubehör Accessoires			
					6		7	8	9	
					farblos non- colored	schwarz black	Kappe Cap	Anzeige-kappe Indicating Cap	Mutterabdeckung Nut Cover	
										
1	2	3	4	5						
Ø	Bild Photo	Maße Dimensions	D Ø	M Ncm	Art.- Nr.	Art.- Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	
9			3 4	80 100	530.3 530.4	530.33 530.43	r 4129.062 sch 4129.063 ga 4129.064 c 4129.065 ge 4129.067 gü 4129.068	r 183529 sch 4129.072 4129.073	ohne Zubehör	
12			3 4 6	80 100 150	531.3 531.4 531.6	531.33 531.43 531.603	r 499.642 sch 499.643 ga 499.644 c 499.645 b 499.646 ge 499.647 gü 499.648	r 18366 sch 18367 ga 18368 sch 531.142 ga 531.143 531.144	ohne Zubehör	
20			6	180	532.6 183966	532.603	r 332.662 sch 332.663 ga 332.664 c 332.665 b 332.666 ge 332.667 gü 332.668	r 183714 sch 183722 ga 183730 sch 532.662 ga 532.663 532.664	 sch 332.120	
28			6 8 10	180 200 250	533.6 533.8 533.9	533.603 533.83 533.93	r 333.662 sch 333.663 ga 333.664 b 333.666 ge 333.667 gü 333.668	r 333.662 sch 333.663 ga 333.664		
36			6 8 10	180 200 250	534.6 534.8 534.9	534.603	r 334.662 sch 334.663 ga 334.664	183712		

10	11	12	13	14
dto. mit Zeiger Same, with pointer	Zeiger Pointer	Zeigerscheibe Pointer dial	glasklare Scheibe Transparent dial	Grundplatte Base plate
				
Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Farbe Color Art.-Nr.	Ausf. Type Maße Dimensions Art.-Nr.	Ausf. Type Art.-Nr.
 sch 332.100 719811 / 183607 r 332.101 719838 ga 332.102		 sch 332.250	 0 332.200 1 332.201 2 332.202 3 332.203 4 332.204 719951 5 332.205	 1 332.300 sch 719886
	 sch 333.100 720313 / 183659 r 333.101 720321 ga 333.102	 sch 333.250	 0 333.200 1 333.201 2 333.202 3 333.203 4 333.204 5 333.205	 1 333.300 sch
	 sch 334.100 183689 r 334.101 ga 334.102		 0 334.200 1 334.201	