


Strangkühlkörper

Extruded Heatsinks

Dissipateurs extrudés

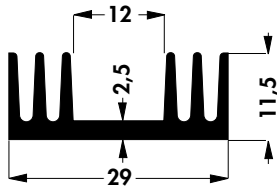


SK 09


20 37,5 50 1000 mm

TO 220 K


SK 09 37,5 TO 220

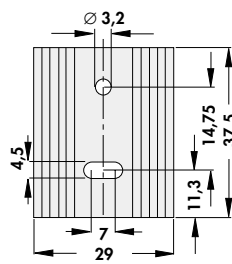




SK 09 37,5 TO 220/1
SK 09 50,0 TO 220/1

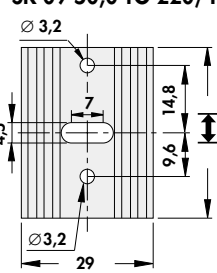

SK 09 50 TO 220

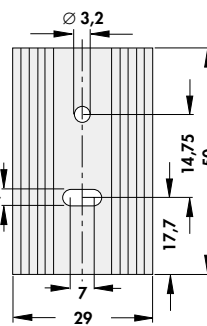

SK 09 20 TO 220

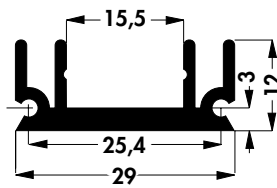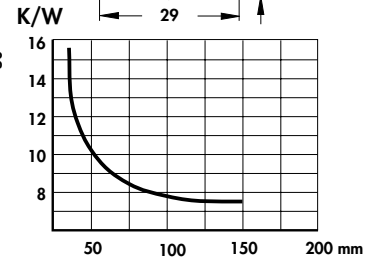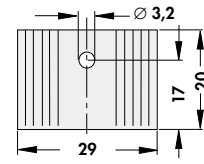


SK 145

20 37,5 50 1000 mm


TO 220

SK 145 mit Lötstiften → A 94



SK 145 20 TO 220

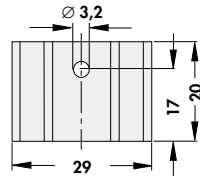

SK 145 37,5 TO 220

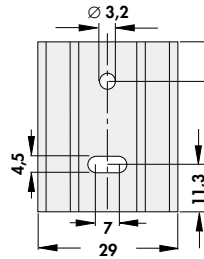

SK 145 50 TO 220

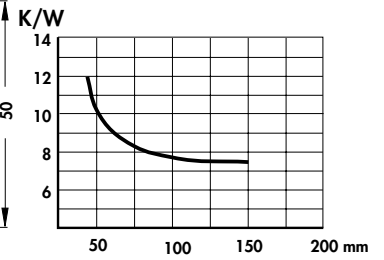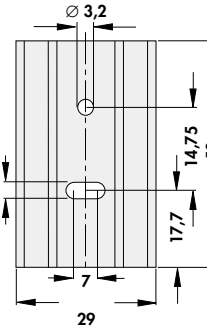



SK 145 with Solder Pins → A 94

SK 145 avec broches à souder → A 94

SK 59

37,5 50 75 100 1000 mm



9/66 TO 220

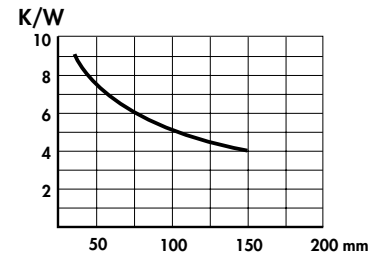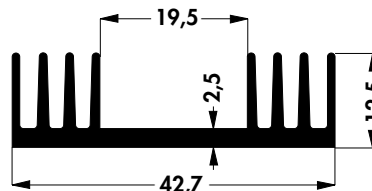

SK 122

37,5 50 100 mm

TO 3 9/66 CB

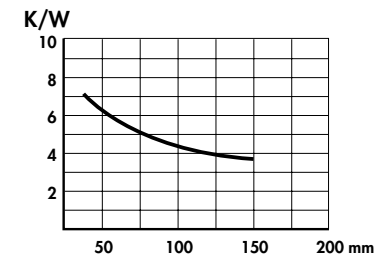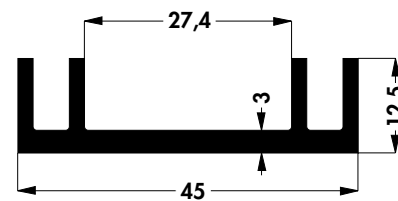

SK 78

37,5 50 75 100 1000 mm

TO 3 9/66 CB

